

Type-C Multifunctional Adapter



PD
fast charge



RJ45
1000Mbps



Data
transmission





Type-C 5 in 1

Multiple device connections

Transfer 1GB Movie in 5 Seconds

3*USB3.0 ports



Mouse



U disk



Keyboard



Hard disk





Fully Charged within 1.5h
for Macbook

87W fast charge, can quickly supply power to PD-enabled devices

Note: All data are from Vention Lab.



Fully Charged within 1.5h for Macbook

87W fast charge, can quickly supply power to PD-enabled devices

Note: All data are from Vention Lab.

Applicable Devices List

Suitable for computer and cellphone with full function Type-C ports

Laptop		Mobile Phone	
Apple	12" MacBook/2017/2018 MacBook Pro Mac mini/2018 MacBook Air	SAMSUNG	Note8/Note9/S8 S8+/S9/S9+/S10/S10+
Huawei	MateBook 13/MateBook/MateBook X MateBook X Pro/MateBook E	HUAWEI	Mate10/Mate10 Pro Mate20/Mate20 Pro Mate20 X/Mate20 RS P20/P20 Pro
Honor	MagicBook		
Xiaomi	Air 12.5"/13.3 "Pro15.6 " 15.6" GTX version Game book 8 generations	Honor	Note 10/V20
HP	Pavilion x2/Spectre 13 EliteBook Folio G1 Envy 13	Microsoft	Microsoft 950XL Microsoft 950
ASUS	Ling Yao 3 U306/U321/U4100/ROG	LG	G5/V300L
Dell	XPS13/XPS15/Latitude 5285	Smartisan	Nut R1/Nut Pro 2S
Lenovo	Xiaoxin Air 12 "Yoga5 Pro/yoga 900 13" Miix 720/ThinkPad_X1 Carbon 2017	OPPO	R17 Pro
SAMSUNG	NoteBook series/GalaxyBook series	iPad	
Google	ChromeBook Pixels/ PixelBook Pen		
Razer	Blade Stealth Blade Spiritblade Sneak Edition	Apple	iPad Pro 2018 11"and 12.9" (Support HDMI)
Microsoft	Surface Book 2/Surface GO	More Type-C models will be continuously updated	
HTC	HTC 10		

Compatible with Multiple Systems



Good Heat Dissipation

Alloy casing+surface anodizing process



Anti-fingerprint



Full load operating temperature
Only about 45 degrees




Wear and corrosion resistant



Note: All data are from Vention Lab.
The specific operating temperature will vary depending on
the environment in which it is used


High Performance Chip

VL817+AX88179A+VL102

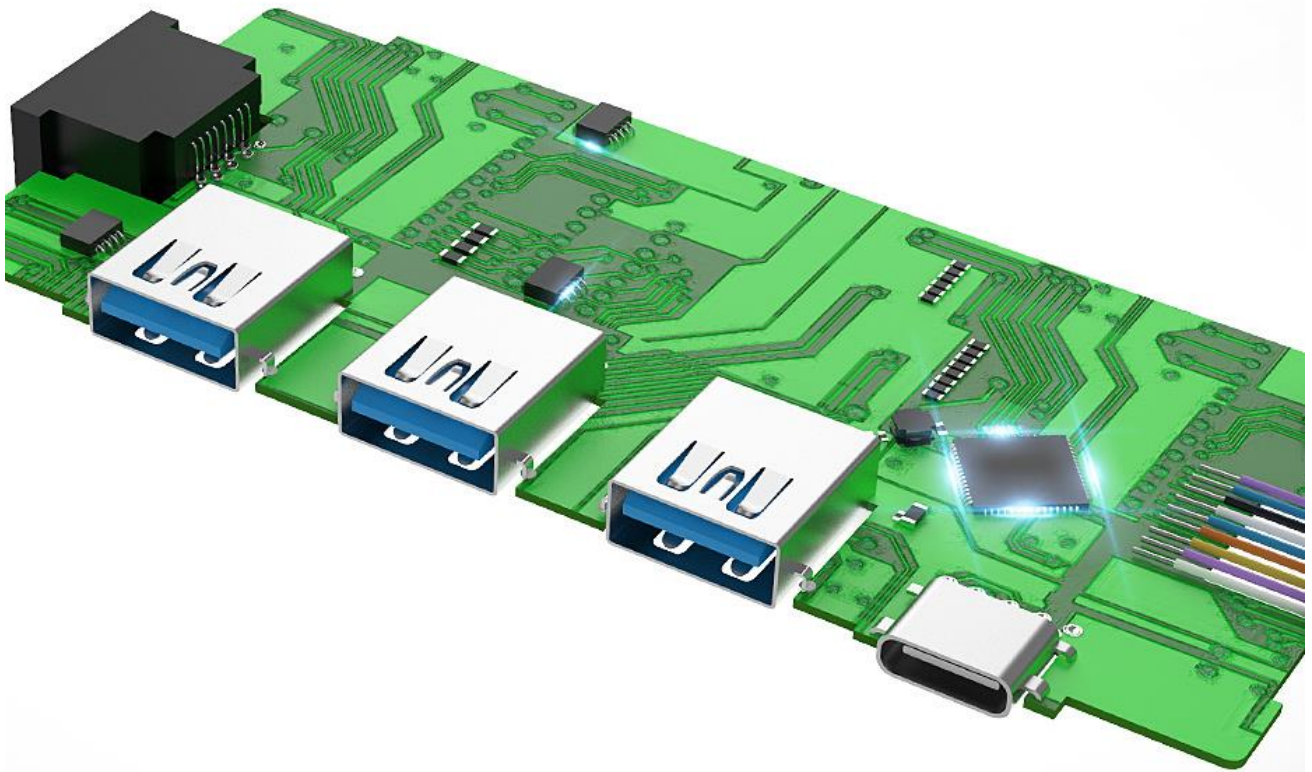

Note: The internal structure is a rendering, please refer to the actual product

Shielding Protection

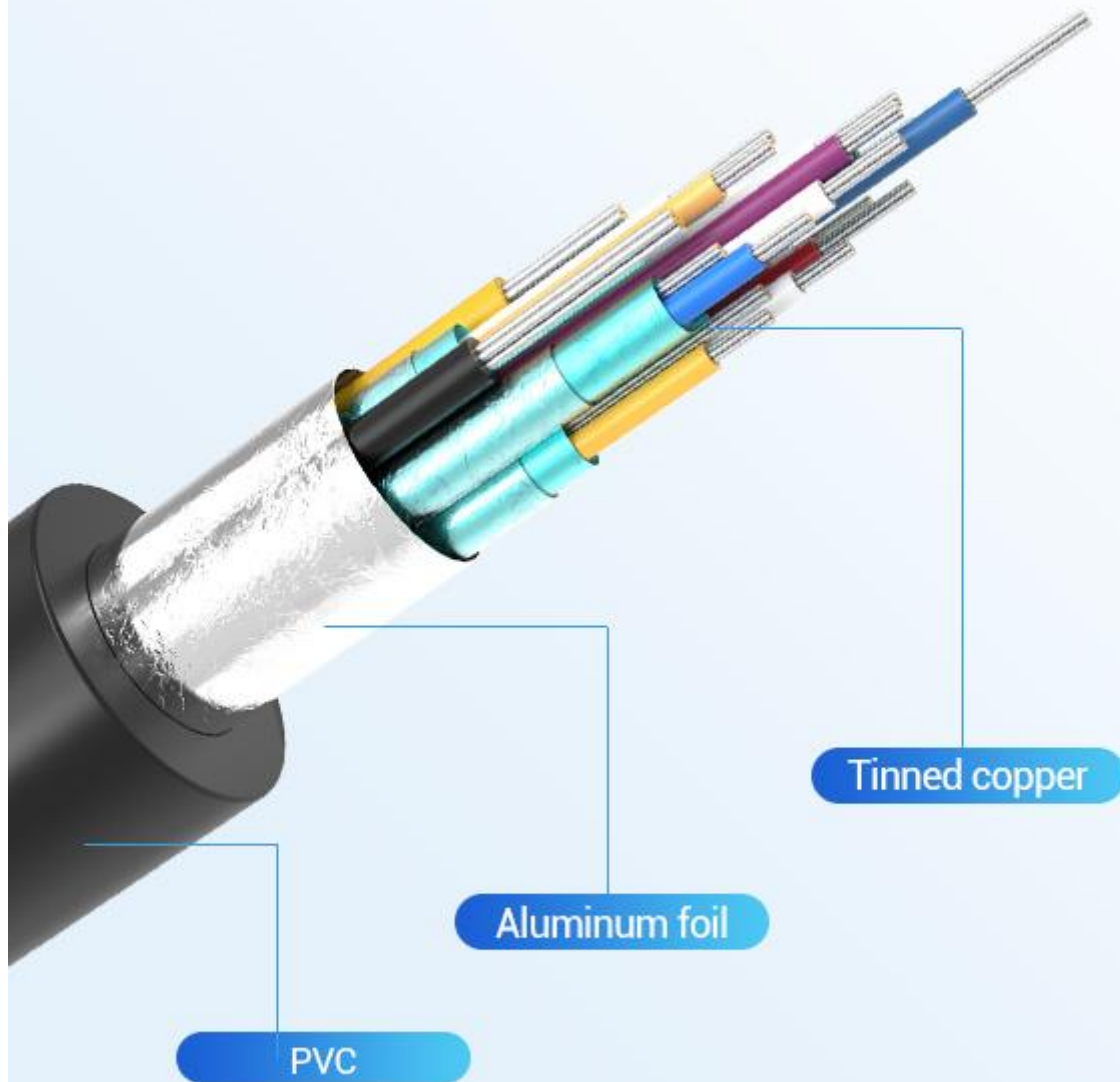

Small and Portable

Easy to fit a briefcase



Product Parameters

Brand: Vention	Shell: Aluminum Alloy + ABS
Name: Type-C to USB3.0*3/RJ45/PD Converter	Chip: IF668+GL3523+RTL8153B
Model: TGDHB	Shielding: Aluminum Foil
Color: Grey	Jacket: PVC
Interface: Type-C, USB3.0*3, RJ45, PD	AWG: 30AWG+24AWG
Version: USB3.0, Gigabit Network	OD: 4.5mm
Interface Technics: Nickel-plated	Length: 0.15m
Transmission Speed: 5Gbps	Power: 87W
Transmission Direction: Type-C to USB3.0/RJ45/PD	Warranty: 1 Year
Conductor: Tinned Copper	Packing: Color Box



Note: All data are from Vention Lab.
Sizes above are manually measured. There might be slight tolerance.



Note: Packing difference exists for different meters or batches.
The photo is for reference only.

Working is Wonderful

[BUY NOW >>](#)





5-in-1 USB-C Hub

Technical Features	
Color	Gray
Interface	USB-C/USB 3.0 x 3/RJ45/PD
Connector Process	Nickel-Plated
Material	Aluminum alloy + ABS
Data transfer rates	5Gbps (USB 3.0)
Power supply	100W PD
Transmission rate	10/100/1000Mbps

Length	Art.No.	EAN Code
0.15m	TGDHB	6922794742604



Package Contents
5-in-1 USB-C Hub x 1

Packaging Information	
Packing Dimension	17.25*9.25*2.75cm
Packing Weight	0.109kg
Carton Dimension	50*37*34cm
Carton Qty	100pcs
Carton Weight	11.9kg