

USB-C 9-in-1 Docking Station

Offer solution to mobile officing



Multiple Functions Extension

Provide enormous potential



Note: All data are from Vention Lab



HDMI port

Switch Supported

Enjoy home video game in large screen



4K High Resolution

Support up to 4K@30Hz via HDMI port



Note: the display devices should also support 4K resolution, all data are from Vention Lab



PD port

100W Fast Charging

Offer charging solution to single-port laptop

Around 1.5 hours
Full of MacBook Pro13"

Around 2 hours
Full of MateBook 13



Note: All data are from Vention Lab

SS 
USB 3.0

USB Peripherals Connection

Connect to super speed USB peripherals



Note: All data are from Vention Lab



RJ45 port

1000Mbps Network

Self adapt 10/100/1000M network



Note: All data are from Vention Lab



TF/SD slots

Support 256G TF/SD Card



Note: All data are from Vention Lab

3.5mm Audio Port

Supports both Mic input and audio output



Note: Support OMTP&CTIA earphones



USB-C port

Large Screen Extension

Turns your phone to PC
convenient for mobile officing



HDMI



USB



PD



Applicable Devices List

Suitable for computer and cellphone with fully functional USB-C ports

	Laptop	Mobile Phone
Apple	MacBook12" MacBook Pro2016/2017/2018/2019 Mac Mini, MacBook Air 2018/2019 /2020	SAMSUNG Note8 Note9 S8/S8+ S9/S9+ S10/S10+ Note10 Note10+
Huawei	MateBook, MateBook E/E 2019 MateBook X/X Pro/X Pro 2019 MateBook 13, MateBook 14	
Honor	MagicBook, MagicBook 2019	Huawei Mate10 Mate10 Pro Mate20 Mate20 Pro Mate20 X Mate20 RS, P20 P20 Pro, Mate X P30, P30 Pro Mate30 Mate30 Pro P40, P40 Pro
Xiaomi	Air12.5"/ 13.3", Pro15.6" GTX version 15.6" Xiaomi game book 8 generation	
HP	Pavilion x2, Spectre 13 EliteBook Folio G1 Elite Book 1050 G1, Envy 13 Shadow Wizard 4 Pro	
ASUS	Ling Yao 3, Ling Yao 3 Pro Ling Yao X series, U306, U321 U4100UN, U5100UQ, ROG	Honor Glory Note 10 Glory V20
Dell	XPS13/15, Latitude 5285, G+C22 G3/G5/G7, Lingyue 5000/7000	Microsoft Microsoft 950XL Microsoft 950
Lenovo	Xiaoxin Air 12", Yoga5 Pro Yoga6 Pro, Yoga 900 13" Miix 720 ThinkPad_X1 Carbon 2017 Saver Y7000/Y7000P/Y9000K	LG G5, V300L
SAMSUNG	NoteBook series GalaxyBook series	Smartisan Nut R1 Nut Pro 2S
Google	ChromeBook Pixels PixelBook Pen	OPPO R17 Pro
Razer	Blade Stealth Spirit Blade Spirit Blade Sneak Edition	BlackShark BlackShark 2
Microsoft	Surface Book 2, Surface GO	iPad
HTC	HTC 10	Apple iPad Pro 2018 /2020
More USB-C models will be continuously updated ...		

Note: Not applicable to Xiaomi / Redmi USB-C mobile phones

More Functions via OTG

Watch movie on phone
without network



Tablet connects
to mouse and keyboard



Phone connects
gamepad



Note: Support the cellphone/tablet with OTG function

High Performance Chips

Stable and fast operation

AG9311

HDMI+PD chip

VL817

3.0 HUB chip

RTL8153

Network chip

FE1.1S


2.0 HUB chip

GL823K

SD/TF chip

HS-100B

3.5mm audio chip

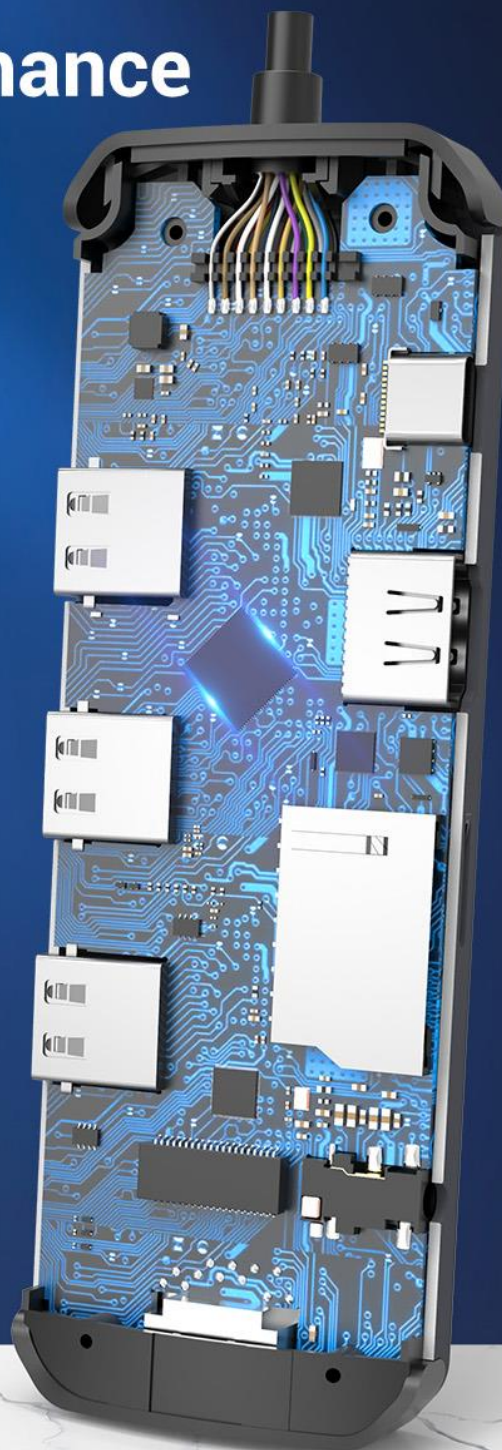

Note: All data are from Vention Lab

More Details

01

Aluminum alloy shell

Good heat dissipation



02

Nickel-plated interface

Wear resistance



03

Small and portable

Easy to carry around

3.5mm Audio Port

Supports both Mic input and audio output



Note: Support 3.5mm OMTP/CTIA TRRS earphones

Product Parameters

Brand:Vention

Name:USB-C to HDMI/USB 3.0x3/RJ45/SD/TF/TRRS 3.5mm/PD Docking Station

Model:TOLHB

Color:Gray

Interface:USB-C/HDMI/USB 3.0/RJ45/TF/SD/PD/TRRS 3.5mm

Interface Technics:Nickel-plated

Resolution:4K@30Hz

USB Transmission rate:5Gbps

Conductor:Tinned-copper

Network Speed:10/100/1000Mbps

Card Version:2.0 UHS-I SD/TF

Compatible Memory Card:Micro SD/Micro SDHC/Micro SDXC/SDHC/SDXC

Card Read:2.0 Single Card Read

Shell:Aluminum Alloy

Chip:G9311+VL817+RTL8153+FE1.1S+GL823K+HS-100B

Shielding:Aluminum Foil+Metal Braided

Jacket:TPE

AWG:24+32AWG

OD:4.5mm

Length:0.15m


Rated Input:PD 100W

Warranty:1 Year

Packing:Kraft Box+Color Box



Note:All data are from Vention Lab.
Sizes above are manually measured.There might be slight tolerance.

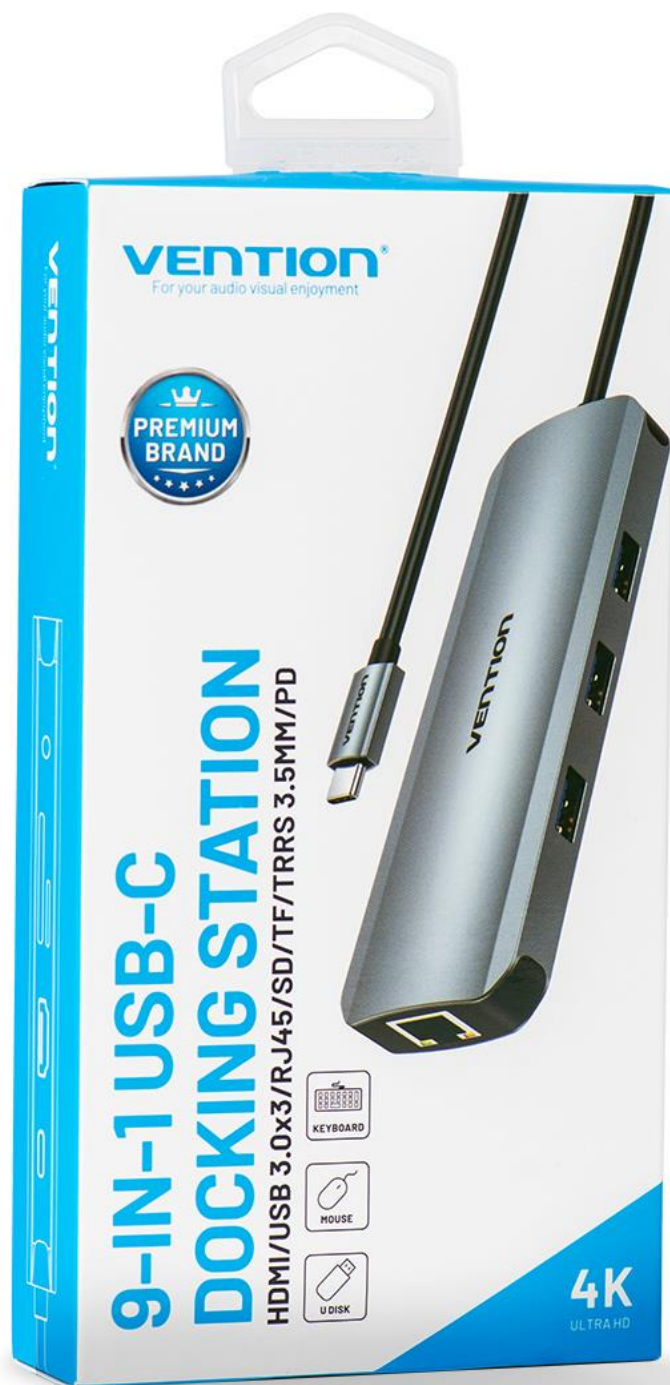

Note: Packing difference exists for different meters or batches.
The photo is for reference only



9-in-1 USB-C Docking Station

Technical Features		
Color	Gray	
Interface	USB-C/HDMI/USB 3.0 x 3/RJ45/SD/TF/3.5mm TRRS/PD	
Connector Process	Nickel-Plated	
Material	Aluminum alloy + ABS	
Data transfer rates	5Gbps (USB 3.0)	
Power supply	100W PD	
Resolution	4K@30Hz	
Card slot type	SD/TF 1-LUN (Read/Write only one card at a time)	
Card slot speed	USB 2.0	
Transmission rate	10/100/1000Mbps	
Compatible audio standard	OMTP&CTIA	
Length	Art.No.	EAN Code
0.15m	TOLHB	6922794753457
Package Contents		
9-in-1 USB-C Docking Station x 1		
Packaging Information		
Packing Dimension	17.25*9.25*2.75cm	
Packing Weight	0.128kg	
Carton Dimension	48*30*30cm	
Carton Qty	70pcs	
Carton Weight	9.96kg	

