

DUT support PAS-02,8-03,0

Item 17990




GO TO PRODUCT

ingun[®]


Partner for Future Technology

- Reliable plastic stamps for supporting PCBs
- Robust, pressure-resistant, trusted design
- Uniform tip height, various tip diameters available
- Suitable for use in ESD protection zones (EPA), due to low electrostatic charge

INGUN SELECTION

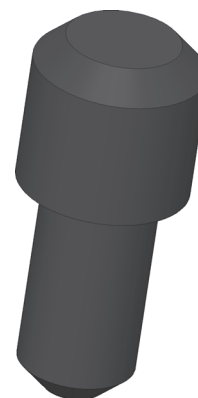

1:1

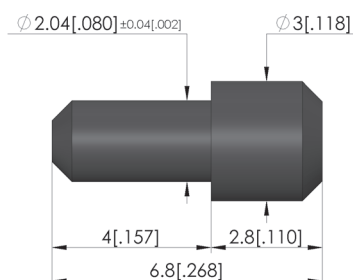

General data

Product group:

Series:

Type:

Version:

Accessory type:

Material:

Min. temperature:

Max. temperature:

RoHS-compliant:

PCB support pin

PAS

DUT support (round)

Suitable for ESD-protected zone

Customising accessory

PA6

+ 10 °C [+ 50 °F]

+ 60 °C [+ 140 °F]

RoHS-3

Technical data

Tip diameter:

Installation:

Length:

Tip height:

Diameter:

3 mm [.118 in]

Pressed in

6.8 mm [.267 in]

2.8 mm [.110 in]

2 mm [.078 in]

Compatible with

Exchangeable kits version:

Manual test fixtures (MA): MA 2009, MA 2011, MA 2012, MA 2013, MA 2013T, MA 2014

Vacuum test fixtures (VA):

MA exchangeable kits (ATS MA):

VA exchangeable kits (ATS VA):

PA exchangeable kits (ATS PA):

No limitations

VA xxxx

ATS MAxx, ATS MAxxx

ATS VINxxx

ATS PAZxxx, ATS PAxxxx

Mounting hole

Mounting hole in CEM1:

Mounting hole in FR4:

1.98 - 1.99 mm [.077 - .078 in]

1.98 - 1.99 mm [.077 - .078 in]

INGUN Prüfmittelbau GmbH

Max-Stromeyer-Straße 162

78467, Constance, Germany

Phone +49 7531 8105-0

Customer hotline +49 7531 8105-888

Fax +49 7531 8105-65

info@ingun.com



Prices and delivery times on request.
Technical changes reserved. 07/24_GB