

Push rod

NHS-ST-60,0-2,5-POM-AL

Item 21615



GO TO PRODUCT

ingun[®]



 
Partner for Future Technology

- Trusted push rods for reliable, rigid fixing of the PCB against the force of the test probes in the probe field
- Robust, pressure-resistant, trusted design
- Quick, easy installation

Verwendung

Niederhalterstempel (NHS) werden im Ausbau verwendet, um elektronische Leiterplatten während der Kontaktierung im Prüfadapter gegen die Kraft der Kontaktstifte sicher zu fixieren. Niederhalterstempel werden in der Niederhalterplatte montiert.

INGUN SELECTION

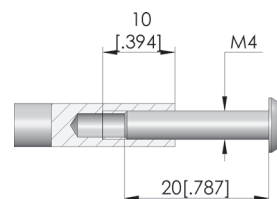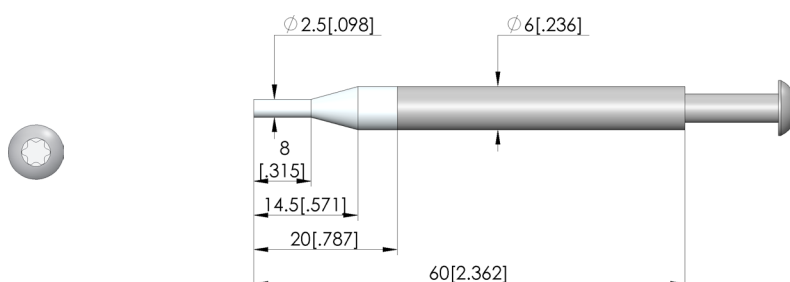

General data

Product group:	Push rods (NHS)
Series:	NHS-ST
Type:	Starr
Version:	Not ESD compliant
Accessory type:	Customising accessory
Scope of delivery:	unmontiert, inkl. M4x20 T20
Outer dimensions (TxL):	6.0 x 60 mm [.236 x 2.36 in]
Colour:	Untreated
RoHS-compliant:	RoHS-3

Technical data

Tip diameter:	2.5 mm [.098 in]
Pushrod shaft diameter:	6 mm [.236 in]
Tip material:	POM
Shaft material:	AL
True running:	2768-mK
Installation:	Screwed in
Thread:	M4x10 mm
Tip length:	20 mm [.787 in]

Mechanical data

Total length:	60 mm [2.36 in]
---------------	-----------------

Compatible with

Exchangeable kits version:	Standard, ESD, RF
Manual test fixtures (MA):	MA 20xx
MA exchangeable kits (ATS MA):	ATS MAxx, ATS MA2xx, ATS MA3xx

Push rod

NHS-ST-60,0-2,5-POM-AL

Item 21615



ingun[®]

Partner for Future Technology



INGUN Prüfmittelbau GmbH

Max-Stromeyer-Straße 162
78467, Constance, Germany
Phone +49 7531 8105-0
Customer hotline +49 7531 8105-888
Fax +49 7531 8105-65
info@ingun.com



Prices and delivery times on request.
Technical changes reserved. 07/24_GB