

DUT support PAS-02,8-05,0

Item 3161




GO TO PRODUCT

ingun[®]



Partner for Future Technology

- Reliable plastic stamps for supporting PCBs
- Robust, pressure-resistant, trusted design
- Uniform tip height, various tip diameters available
- Suitable for use in ESD protection zones (EPA), due to low electrostatic charge

INGUN SELECTION

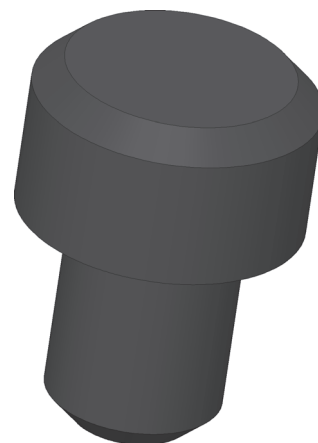

1:1

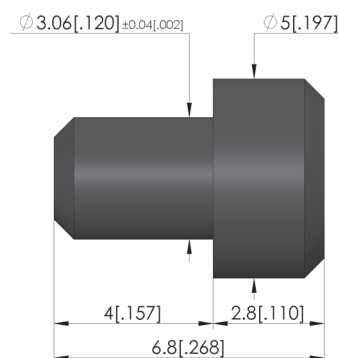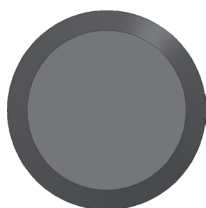

General data

Product group:	PCB support pin
Series:	PAS
Type:	DUT support (round)
Version:	Suitable for ESD-protected zone
Accessory type:	Customising accessory
Material:	PA6
Min. temperature:	+ 10 °C [+ 50 °F]
Max. temperature:	+ 60 °C [+ 140 °F]
RoHS-compliant:	RoHS-3

Mounting hole

Mounting hole in CEM1:	2.98 - 2.99 mm [.117 - .117 in]
Mounting hole in FR4:	2.98 - 2.99 mm [.117 - .117 in]

Technical data

Tip diameter:	5 mm [.196 in]
Installation:	Pressed in
Length:	6.8 mm [.267 in]
Tip height:	2.8 mm [.110 in]
Diameter:	3 mm [.118 in]

Compatible with

Exchangeable kits version:	No limitations
Manual test fixtures (MA):	MA 2009, MA 2011, MA 2012, MA 2013, MA 2013T, MA 2014
Vacuum test fixtures (VA):	VA xxxx
MA exchangeable kits (ATS MA):	ATS MAxx, ATS MAxxx
VA exchangeable kits (ATS VA):	ATS VINxxx
PA exchangeable kits (ATS PA):	ATS PAZxxx, ATS PAxxxx

INGUN Prüfmittelbau GmbH

Max-Stromeyer-Straße 162
78467, Constance, Germany
Phone +49 7531 8105-0
Customer hotline +49 7531 8105-888
Fax +49 7531 8105-65
info@ingun.com



Prices and delivery times on request.
Technical changes reserved. 07/24_GB