


Data sheet Product CAB 4 G S

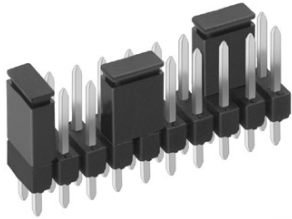

PCB connectors>Jumpers
pitch 2.54 mm; for 0.6...0.64 mm wire wrap pins and Ø 0.6...0.7 mm The flexible contacts are shorting two pins. The jumpers can be mounted behind and next to each other.

Features

pitch:	2.54 mm
surface of contact:	0.1 µm gold
surface contact / contact sleeve:	• 0.1 µm Au • 5 µm Sn
no. of contacts:	2
version:	closed
insert depth:	4...6.1mm
nominal current:	1.5 A
nominal voltage:	250 V AC
insulating body material:	PBT
temperature range:	-40°C... +105°C
colour:	black
reflow solderable:	no

Technical Drawing

