

Addressable SK6812 RGB LED Strip-30LEDs/m



Product Description :

This addressable LED strip has 30pcs SMD5050 RGB LED chips, 30pixels per meter, each Single LED per unit and cut-able

The PCB is 1+1 Ounce thick copper

All the soldering pads are very large

White & Black PCB, DC5V voltage

5 Meters per reel, customized sizes are also available


3Pin JST SM male/female connector

IP Rate: IP20, IP64, IP65

Product Datasheet

Product Number	S010030CA3SA1	Luminance/M	R: 32lm G: 90lm B: 19lm
Operating Voltage	DC5V	Ra	/
Power/M	6W	Beam Angle	120°
SMD Type	SMD 5050	Size (mm)	5000 * 10mm
LED Qty/M	30	IP Rate	IP20/IP64/IP65
Color	RGB	Operation Temperature	- 25 ~ 60 °C
Pixel/M	30	Material	FPC
Control	WS2812B/SK6812	Cutting Length	33.3mm
Wavelength	R:620-625 G:520-525 B:460-465nm	Net Weight/Roll	0.13KG


Outline Dimension (unit: mm)

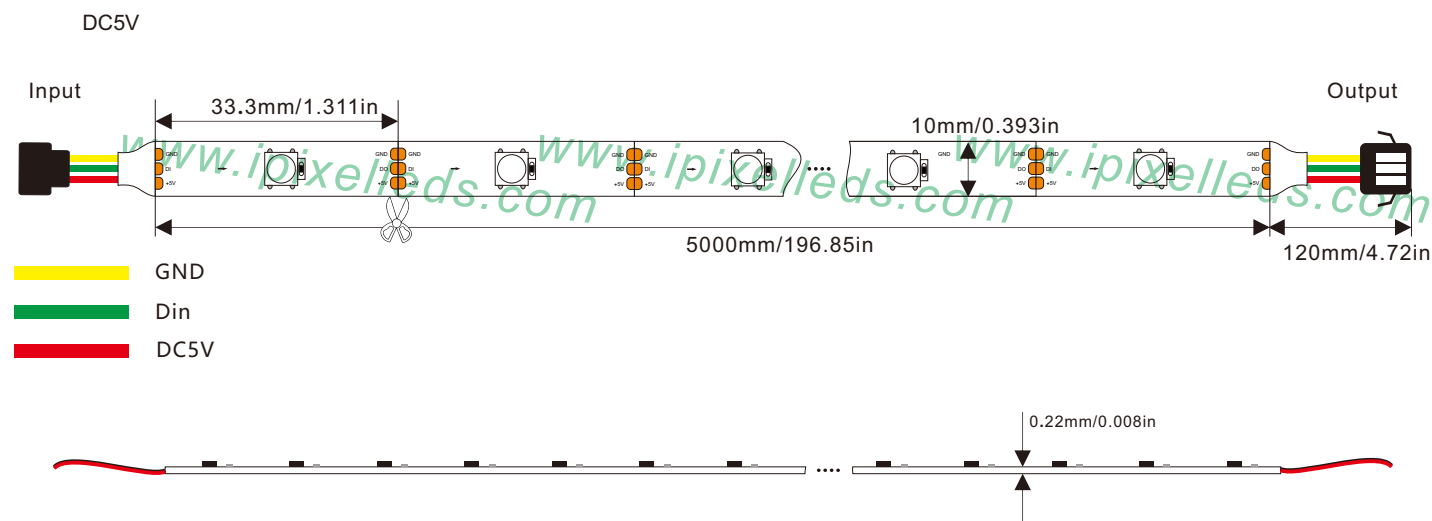


◆ Order number

DC5V	RGB	White PCB	IP20	S010030CA3SA1/C1
DC5V	RGB	White PCB	IP64	S010030CA3SA1/C2
DC5V	RGB	White PCB	IP65	S010030CA3SA1/C3
DC5V	RGB	Black PCB	IP20	S010030CA3SA1/C4
DC5V	RGB	Black PCB	IP64	S010030CA3SA1/C5
DC5V	RGB	Black PCB	IP65	S010030CA3SA1/C6

◆ Wiring diagram

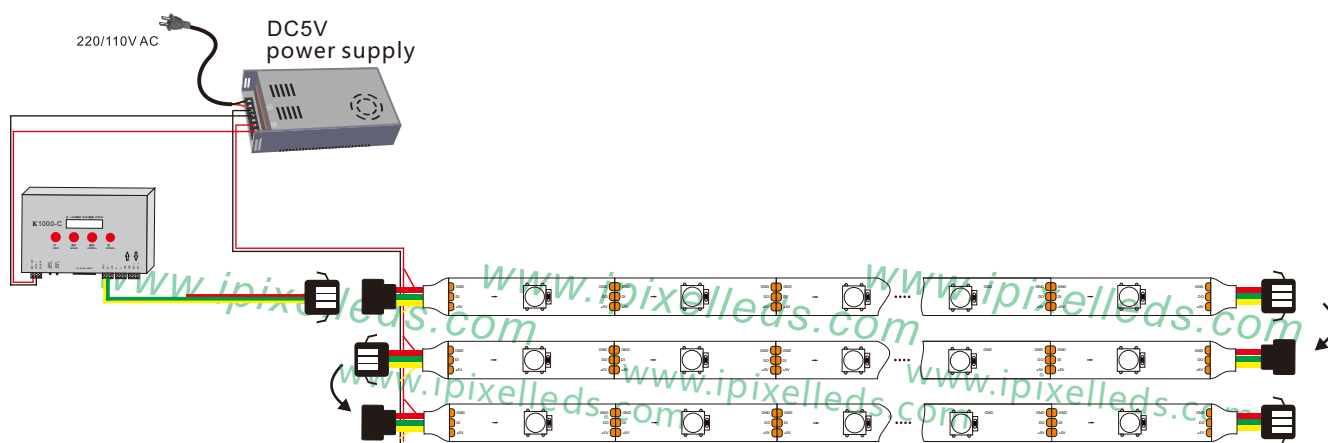

◆ Strip IP Rate

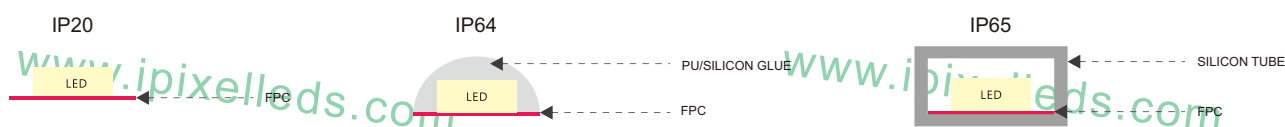

◆ Accessories



Screw



Silicone clip



End cap

Note: The parameters are subject to change without notice!