

WS2811 DC12V RGB Digital LED Strip-30LEDs/m




Product Description :

This digital led strip has 30pcs 5050 RGB LED chips & 10pixels per meter, SPI control
 3LEDs per section, can be cut every 100mm
 White & black PCB board are available
 5m per reel and 3M tape is included
 JST SM connector on each side
 DC12V constant voltage operation
 Silicon coating, silicon tube housing, silicone injecti on waterproof

Product Datasheet

Product Number	S010030CB3SF	Luminance/M	R: 43lm G: 120lm B: 20lm
Operating Voltage	DC12V	Ra	/
Power/M	7.2W	Beam Angle	120°
SMD Type	SMD 5050	Size (mm)	5000 * 10mm
LED Qty/M	30	IP Rate	IP20/IP64/IP65/IP67
Color	RGB	Operation Temperature	- 25 ~ 60 °C
Pixel/M	10	Material	FPC
Control	SPI - WS2811	Cutting Length	100mm
Wavelength	R:620-625 G:520-525 B:460-465nm	Net Weight/Roll	0.13KG


Outline Dimension (unit: mm)

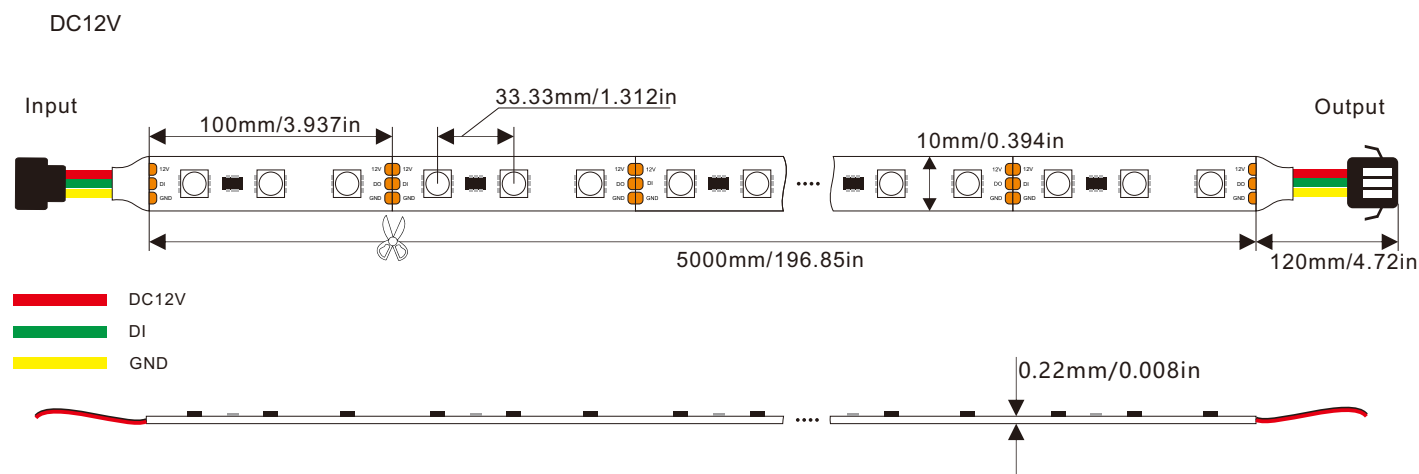


Order number

DC12V	RGB	White PCB	IP20	S010030CB3SF/C1
DC12V	RGB	White PCB	IP64	S010030CB3SF/C2
DC12V	RGB	White PCB	IP65	S010030CB3SF/C3
DC12V	RGB	White PCB	IP67	S010030CB3SF/C4
DC12V	RGB	Black PCB	IP20	S010030CB3SF/C5
DC12V	RGB	Black PCB	IP64	S010030CB3SF/C6
DC12V	RGB	Black PCB	IP65	S010030CB3SF/C7
DC12V	RGB	Black PCB	IP67	S010030CB3SF/C8

Wiring diagram

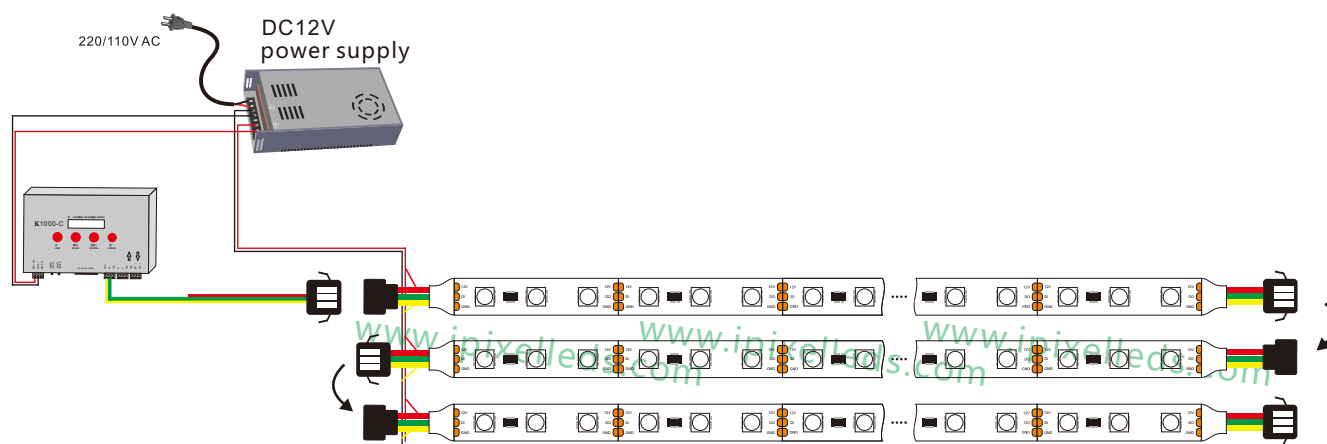

Strip IP Rate

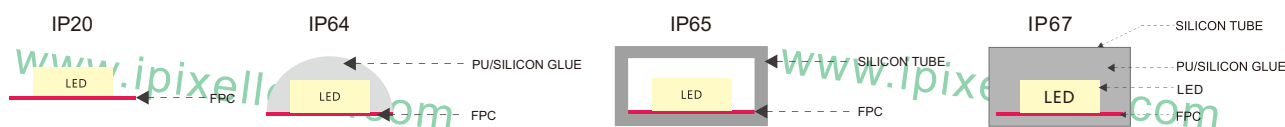

Accessories



Screw



Silicone clip



End cap

Note: The parameters are subject to change without notice!