

Addressable SK6812 RGB LED Strip- 60LEDs/m



Product Description :

This addressable LED strip has 60pcs SMD5050 RGB LED chips, 60pixels per meter
 Each single LED per unit and cut-able, the PCB is 1+2 Ounce thick copper
 All the soldering Pads are very large
 White & Black PCB, DC5V voltage
 5 Meters per reel, customized sizes are also available
 3Pin JST SM male/female connector
 IP Rate: IP20, IP64, IP65




Product Datasheet

Product Number	S010060CA3SA1	Luminance/M	R:24000 G:42000 B:11400lm
Operating Voltage	DC5V	Ra	/
Power/M	14.4W	Beam Angle	120°
SMD Type	SMD 5050	Size (mm)	5000 * 10mm
LED Qty/M	60	IP Rate	IP20/IP64/IP65
Color	RGB	Operation Temperature	- 25 ~ 60 °C
Pixel/M	60	Material	FPC
Control	SK6812	Cutting Length	16.67mm
Wavelength	R:620-625 G:520-525 B:460-465NM	Net Weight/Roll	0.13KG

Outline Dimension (unit: mm)

DC5V

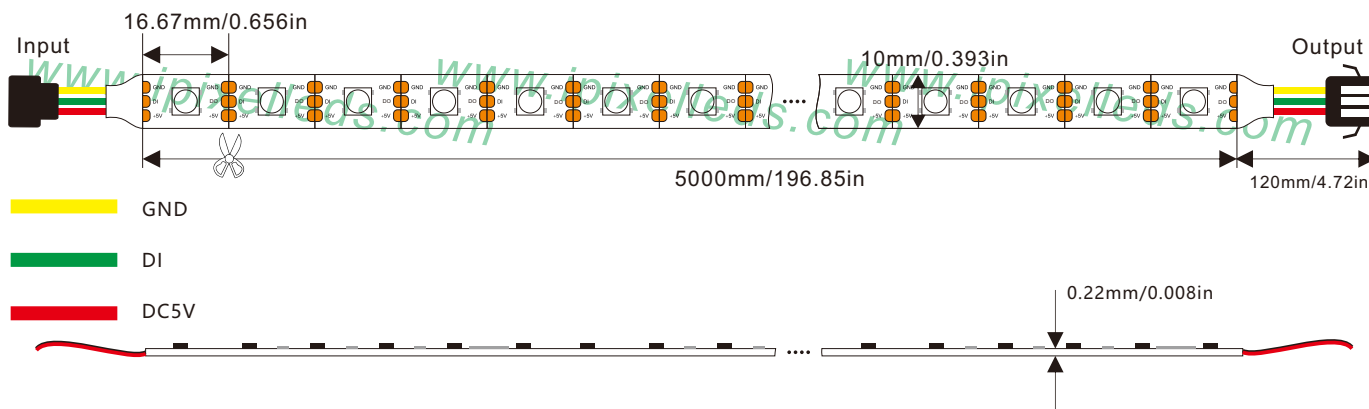

◆ Order number

DC5V	RGB	White PCB	IP20	S010060CA3SA1/C1
DC5V	RGB	White PCB	IP64	S010060CA3SA1/C2
DC5V	RGB	White PCB	IP65	S010060CA3SA1/C3
DC5V	RGB	Black PCB	IP20	S010060CA3SA1/C4
DC5V	RGB	Black PCB	IP64	S010060CA3SA1/C5
DC5V	RGB	Black PCB	IP65	S010060CA3SA1/C6

◆ Wiring diagram



◆ Strip IP Rate



◆ Accessories



Screw



Silicone clip



End cap

Note: The parameters are subject to change without notice!