


DC12V WS2811 Digital RGB LED Strip-60LEDs/m

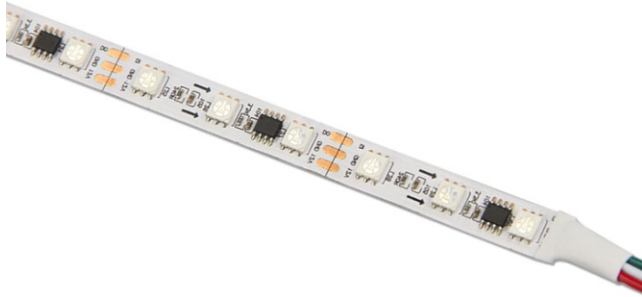

Product Description :

This digital led strip has 60pcs 5050 RGB LED Chips per meter

SPI Control, 3LEDs&1Pixel per section, 20pixels/m

Can be cut every 50mm, white & black PCB board are available

5 m per reel, 3M tape is included

JST SM connector on each side,

DC12V constant voltage operation


Silicon coating, silicon tube housing, silicone injection waterproof



Product Datasheet

Product Number	S010060CB3SF	Luminance/M	R: 95lm G: 254lm B: 44lm
Operating Voltage	DC12V	Ra	/
Power/M	12W	Beam Angle	120°
SMD Type	SMD 5050	Size (mm)	5000 * 10mm
LED Qty/M	60	IP Rate	IP20/IP64/IP65/IP67
Color	RGB	Operation Temperature	- 25 ~ 60 °C
Pixel/M	20	Material	FPC
Control	SPI-WS2811	Cutting Length	50mm
Wavelength	R:620-625 G:520-525 B:460-465nm	Net Weight/Roll	0.24KG


Outline Dimension (unit: mm)

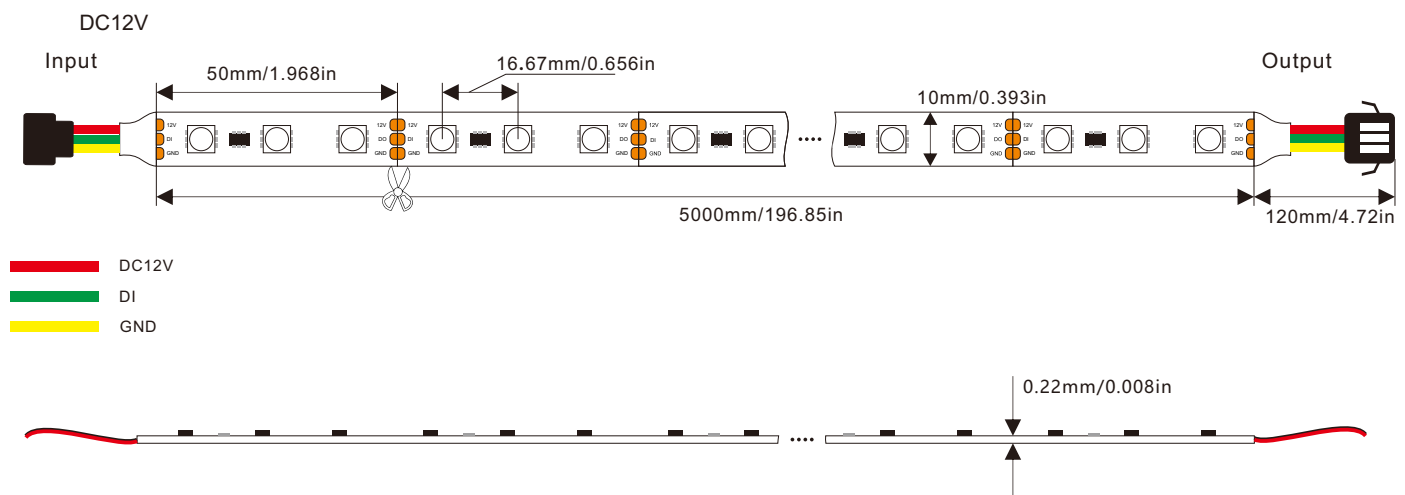


◆ Order number

DC12V	RGB	White PCB	IP20	S010060CB3SF/C1
DC12V	RGB	White PCB	IP64	S010060CB3SF/C2
DC12V	RGB	White PCB	IP65	S010060CB3SF/C3
DC12V	RGB	White PCB	IP67	S010060CB3SF/C4
DC12V	RGB	Black PCB	IP20	S010060CB3SF/C5
DC12V	RGB	Black PCB	IP64	S010060CB3SF/C6
DC12V	RGB	Black PCB	IP65	S010060CB3SF/C7
DC12V	RGB	Black PCB	IP67	S010060CB3SF/C8

◆ Wiring diagram

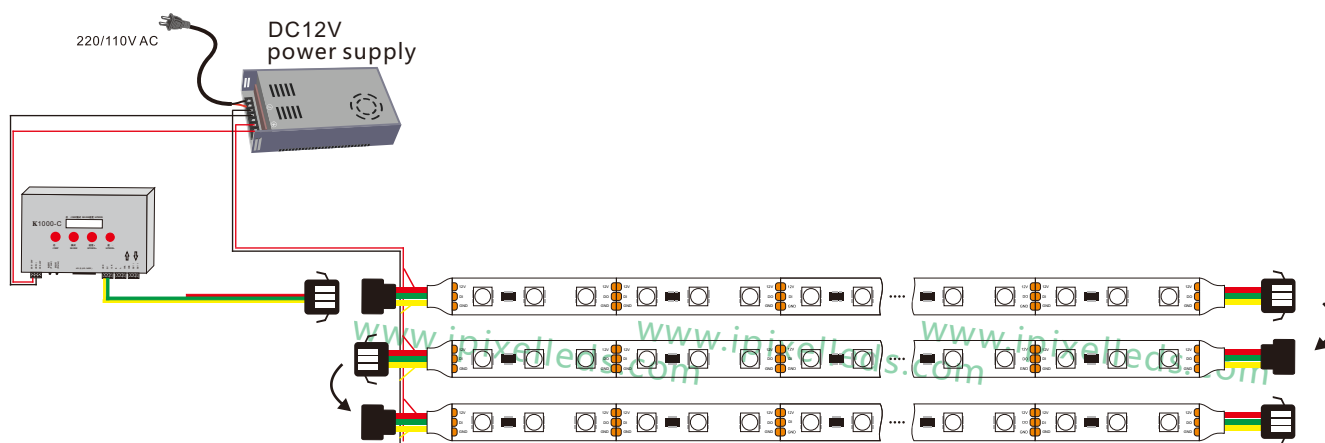

◆ Strip IP Rate

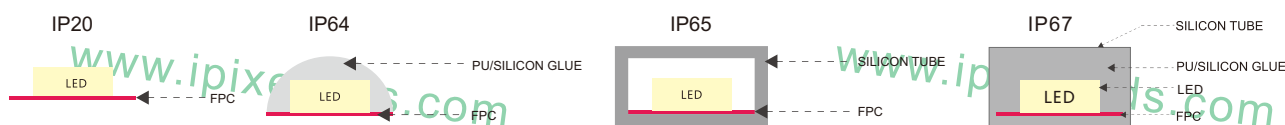

◆ Accessories



Screw



Silicone clip



End cap

Note: The parameters are subject to change without notice!