

10*20mm RGBW Side View

LED Neon strip DC24V



◆ Product Description

Silicone Neon LED flex made by extrusion, white color body, diffused color on the top side

without light spot, it's bendable within limited semidiameter, Anti-UV and salt

It's a 4 in 1 RGBW LED tape inside, no Pixel control, each small section can be cut down

The standard size is 5 meters included 10pcs mounting clips


5Pin bare wire output from each side of the body

◆ Product Datasheet

Product Number	N010060CC4PZ	Luminance/M	R:91 G:155 B:37 W:322lm
Operating Voltage	DC24V	Ra	/
Power/M	19.2W	Beam Angle	120°
SMD Type	SMD 5050	Size (mm)	5000x10x20mm
LED Qty/M	60	IP Rate	IP65
Color	RGB+W:3000K/4000K/6000K	Operation Temperature	- 25 ~ 60 °C
Pixel/M	/	Material	Silicone
Control	PWM	Cutting Length	100mm
Wavelength	R:620-625 G:520-525 B:460-465nm	Net Weight/Roll	1.2Kg

◆ Outline Dimension unit mm


DC24V

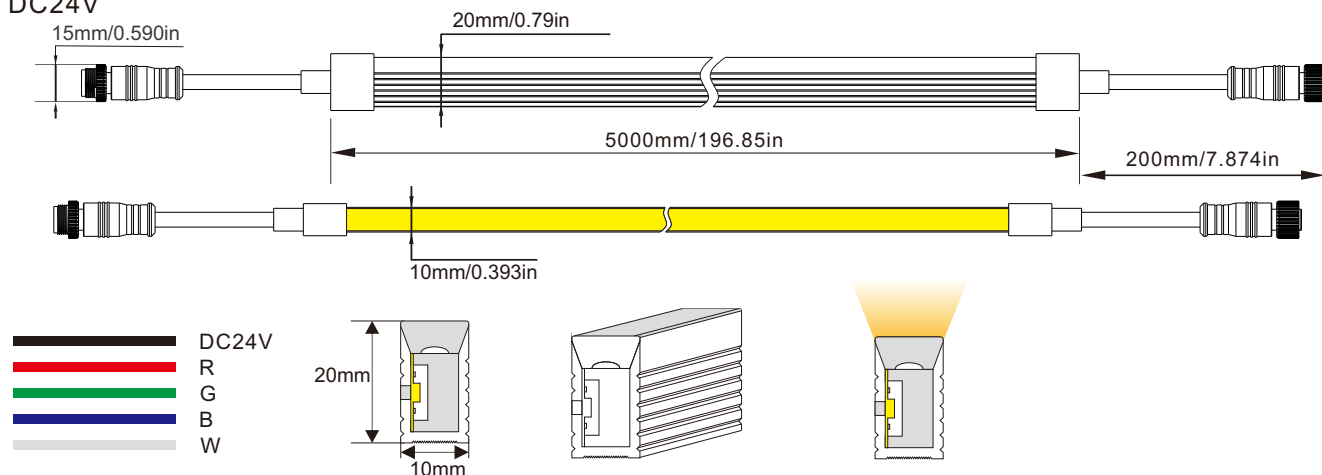


◆ Order number

DC24V	RGB+W:3000K	White PCB	IP65	N010060CC4PZ/C1
DC24V	RGB+W:4000K	White PCB	IP65	N010060CC4PZ/C2
DC24V	RGB+W:6000K	White PCB	IP65	N010060CC4PZ/C3

◆ Wiring diagram


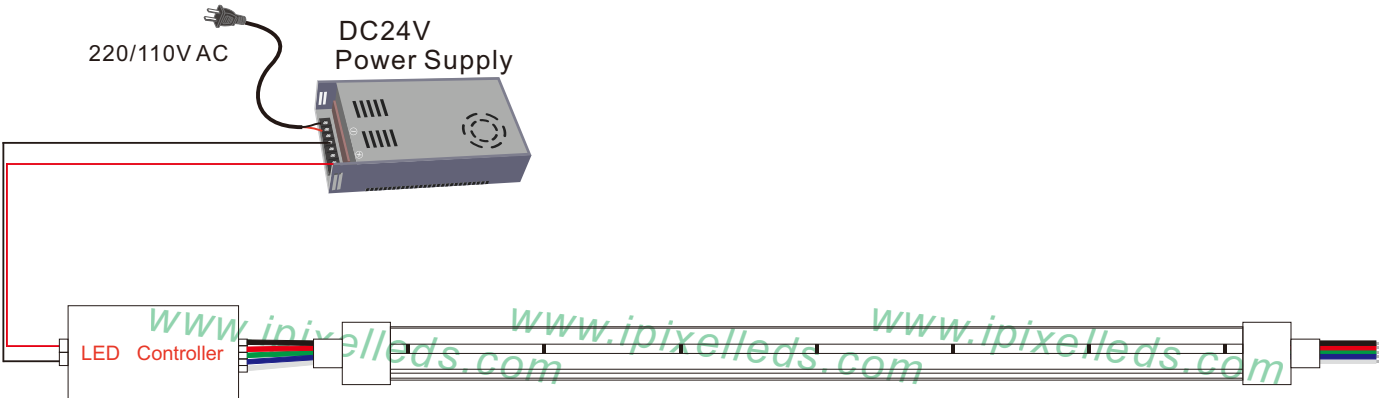


◆ Accessories

 Name	Stainless steel clip	The front cover	End cap	Aluminum profile(1M/pcs)
Picture	standard 	standard 		
Remarks	L30.2xW10.6xH14.6mm			W12xH22.5mm

Note: The parameters are subject to change without notice!

◆ Correct bending way

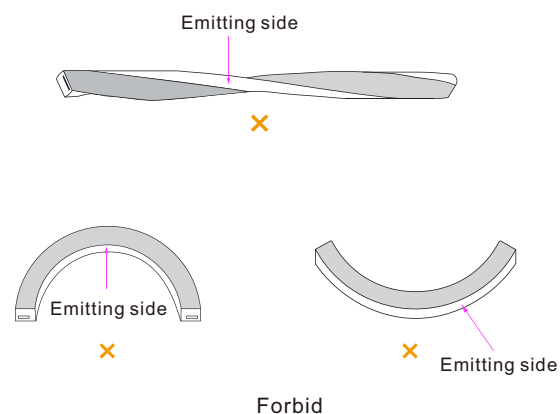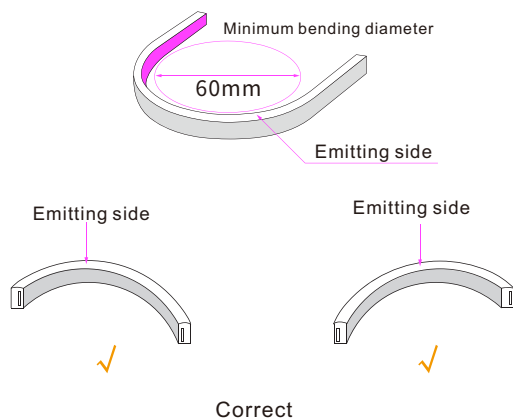



◆ Accessories



Stainless steel clip
30.2x10.6x14.6mm(LxWxH)



Aluminum profile
1000x10.6x14.6mm(LxWxH)

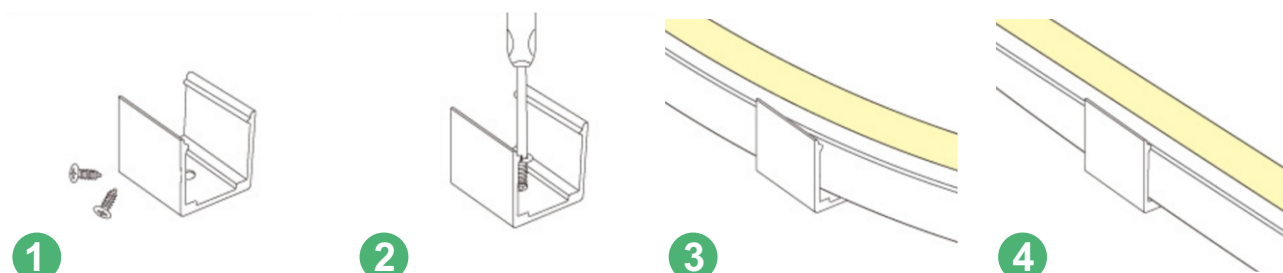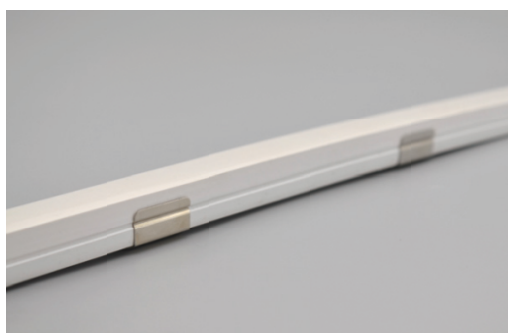

Note: The parameters are subject to change without notice!