

Pushbutton Ø 16 mm silver contact

82-4162.1000.B001



<https://eao.com/p/82-4162.1000.B001>

Your product:



82-4162.1000.B001

Pushbutton Ø 16 mm silver contact

FRONT

Front bezel shape:	flush
Front bezel material:	Stainless steel

MOUNTING

Mounting cut-out:	Ø 16 mm
-------------------	---------

OPERATING-/INDICATION PART

Lens colour:	Silver
Lens optics:	opaque
Lens material:	Stainless steel
Lens shape:	raised
Lens illumination:	non illuminative

ELECTRICAL CHARACTERISTICS

Rated Operational Voltage U _e :	250 VAC
Electric strength:	1500 VAC, 50 Hz 1 minute between life terminals and ground
Electrical lifetime:	50 000 cycles of operation
Pollution degree:	2, according to EN IEC 60947-1
Contacts:	1 C
Thermal current I _{th} :	5 A
Rated insulation voltage U _i :	250 V
Switching voltage and switching current:	

according to IEC 60947-5-1 (Silver contacts)	
Service categorie AC-15	
Voltage	Current
24 VAC	1 A
35 VAC	1 A (M12 version)
110 VAC	1 A
220 VAC	0.5 A
Switch rating DC service categorie DC-13 (Silver contacts)	
Voltage	Current
24 VDC	0.7 A
35 VDC	0.5 A (M12 version)
110 VDC	0.2 A
220 VDC	0.1 A

according to UL 508 (Silver contacts)	
cosφ 0,75 ... 0,8	
Voltage	Current
120 VAC	5 A
240 VAC	3 A
24 VAC	1 A

MECHANICAL CHARACTERISTIC

Switching action:	Momentary
Operating Travel:	ca. 3 mm
Tightening torque:	0.5 ... 0.6 Nm, Screw terminal 0.1 Nm
Weight:	0.02 kg
Contact material:	Silver
Switching system:	Snap-action switching element
Terminal:	Screw terminal
Operating force:	4 N ... 7 N
Mechanical lifetime:	1 Mio. cycles of operation

AMBIENT CONDITION

Storage temperature:	– 40 °C ... + 80 °C
Vibration resistance:	10 ... 500 Hz, amplitude 1.5 mm p-p according to IEC 60068-2-6
Operating temperature:	– 30 °C ... + 70 °C
Climate resistance:	Damp heat, 21 days according to IEC 60512-11
Shock resistance:	Max. 500 m / s ² as per IEC 60068-2-27

CERTIFICATE

Approbations:	CB, CCC, C UL, UL
----------------------	-------------------

Conformities:

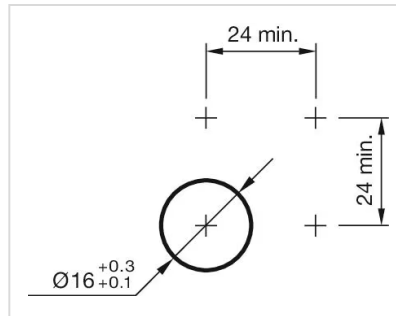
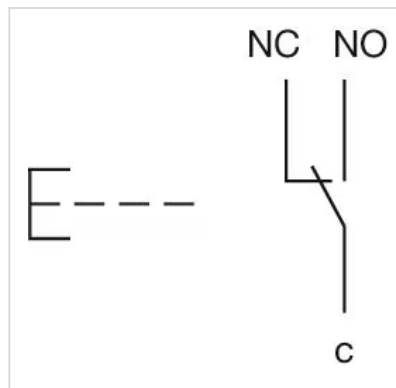
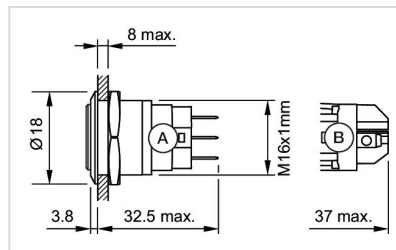
CE, 2011 / 65 / EC (RoHS), 2014 / 35 / EU (LVD)

OTHER**Short Description:**

Pushbutton Ø 16 mm silver contact, Momentary, 1 C, Screw terminal, Stainless steel, ON/OFF, Silver

Symbol:

ON/OFF

Mounting cut-outs:**Wiring diagrams:****Dimension drawings:**A = Solder terminal
B = Screw terminal**Component layouts:**

