

Illuminated pushbutton Ø 22 mm silver contact

82-6552.1134



<https://eao.com/p/82-6552.1134>

Your product:



82-6552.1134
Illuminated pushbutton Ø
22 mm silver contact

FRONT

Front bezel material:	Aluminium
Front bezel shape:	flush

MOUNTING

Mounting cut-out:	Ø 22 mm
-------------------	---------

OPERATING-/INDICATION PART

Lens optics:	opaque
Lens material:	Aluminium
Lens shape:	flush
Shape of illumination:	Ring
Lens colour:	Nature
Lens illumination:	illuminative
Illumination colour:	Green

ELECTRICAL CHARACTERISTICS

Switching voltage and switching current:	according to IEC 60947-5-1 (Silver contacts)	
	Service categorie AC-15	
	Voltage	Current
	24 VAC	1 A
	35 VAC	1 A (M12 versio
	110 VAC	1 A
	220 VAC	0.5 A
	Switch rating DC service categorie DC-13 (Silver contacts)	
	Voltage	Current
	24 VDC	0.7 A
	35 VDC	0.5 A (M12 vers
	110 VDC	0.2 A
	220 VDC	0.1 A

according to UL 508 (Silver contacts)

$\cos\phi$ 0,75 ... 0,8

Voltage

120 VAC

240 VAC

24 VAC

Current

5 A

3 A

1 A

Rated insulation voltage U_i:	250 V
Electric strength:	1500 VAC, 50 Hz 1 minute between life terminals and ground
Operating voltage:	24 V AC/DC
Pollution degree:	2, according to EN IEC 60947-1
Thermal current I_{th}:	5 A
Electrical lifetime:	50 000 cycles of operation
Contacts:	1 C
Rated Operational Voltage U_e:	250 VAC

MECHANICAL CHARACTERISTIC

Operating Travel:	ca. 3 mm
Operating force:	4 N ... 7 N
Terminal:	Screw terminal
Switching action:	Momentary
Switching system:	Snap-action switching element
Tightening torque:	0.5 ... 0.6 Nm
Weight:	0.018 kg
Contact material:	Silver

AMBIENT CONDITION

Operating temperature:	- 30 °C ... + 70 °C
Vibration resistance:	10 ... 500 Hz, amplitude 1.5 mm p-p according to IEC 60068-2-6
Shock resistance:	Max. 500 m / s ² as per IEC 60068-2-27
Climate resistance:	Damp heat, 21 days according to IEC 60512-11
Storage temperature:	- 40 °C ... + 80 °C

CERTIFICATE

Approbations:	CB, CCC, C UL, UL
----------------------	-------------------

Conformities:

CE, 2011 / 65 / EC (RoHS), 2014 / 35 / EU (LVD)

OTHER


Kind of illumination:

Single-LED


Short Description:

Illuminated pushbutton Ø 22 mm silver contact, Momentary, 24 V AC/DC, 1 C, Screw terminal, Aluminium, Green, Nature


Mounting cut-outs:

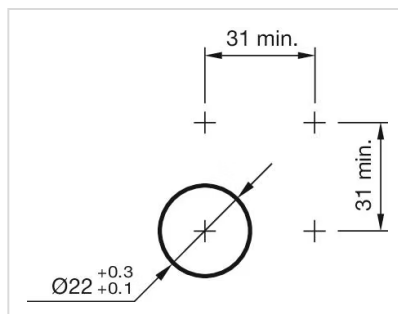

Component layouts:

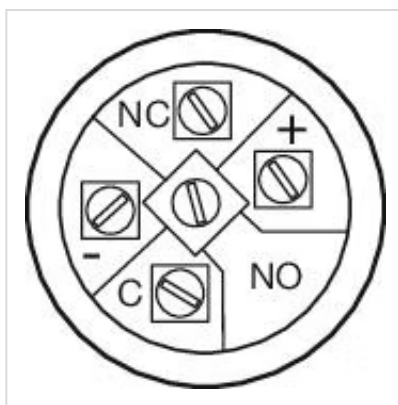

Dimension drawings:

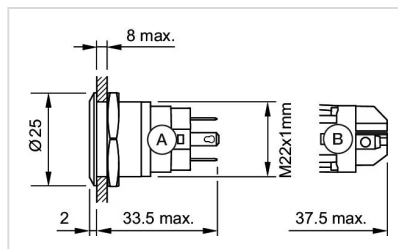

A = Solder terminal
B = Screw terminal

Wiring diagrams:

