

Actuator

46-
2234.11N0.000



<https://testing.eao.com/p/46-2234.11N0.000>

Your product:



46-2234.11N0.000 Actuator

FRONT

Front bezel colour:	Black
Front bezel material:	Plastic
Front form:	round
Front dimension:	Ø 29 mm

MOUNTING

Mounting cut-out:	Ø 22.3 mm
Design:	raised

OPERATING-/INDICATION PART

Lens shape:	flush
Lens optics:	transparent
Lens illumination:	illuminative
Lens material:	Plastic
Lens colour:	White

ELECTRICAL CHARACTERISTICS

Protection class:	II
-------------------	----

MECHANICAL CHARACTERISTIC

Weight:	0.019 kg
Switching action:	Maintained

Mechanical lifetime:	500 000 cycles of operation
Tightening torque:	2 ... 3 Nm (17.7 ... 26.6 Lb-in)

AMBIENT CONDITION


IK front protection:	IK03
Shock resistance:	30g, 18ms (EN-IEC 60068-2-27) 50g, 11ms (EN-IEC 60068-2-27)
Vibration resistance:	5g f= 2...500Hz (EN-IEC 60068-2-6)
Climate resistance:	+25°C-97%RH / +45°C-93%RH (IEC-EN60068-2-30)
IP front protection:	IP65
Operating temperature:	– 25 °C ... + 55 °C

CERTIFICATE

Approbations:	CSA, EAC, UL
Conformities:	CE
Standards:	CSA C22-2, IEC EN 60947-1, IEC EN 60947-5-1, UL508

OTHER

Short Description:	Actuator, Ø 22.3 mm, Ø 29 mm, flush, illuminative, White, Plastic, transparent, round, Black, Plastic, Maintained, IP65, IK03
Housing material:	Plastic
max. number of switching elements:	4
Housing colour:	Black
Dimension drawings:	

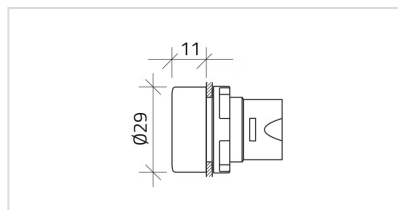

Mounting cut-outs:

