

Actuator

46-

2531.1950.000



<https://testing.eao.com/p/46-2531.1950.000>

Your product:



46-2531.1950.000 Actuator

FRONT

Front form:	round
Front bezel colour:	Black
Front dimension:	Ø 40 mm
Front bezel material:	Plastic

MOUNTING

Design:	raised
Mounting cut-out:	Ø 22.3 mm

OPERATING-/INDICATION PART

Lens colour:	Green
Lens shape:	mushroom-head
Lens illumination:	non illuminative
Lens material:	Plastic
Lens optics:	opaque

ELECTRICAL CHARACTERISTICS

Protection class:	II
-------------------	----

MECHANICAL CHARACTERISTIC

Mechanical lifetime:	1 Mio. cycles of operation
Tightening torque:	2 ... 3 Nm (17.7 ... 26.6 Lb-in)

Switching action: Momentary

Weight: 0.036 kg

AMBIENT CONDITION

IP front protection: IP65

Operating temperature: - 25 °C ... + 55 °C

Vibration resistance: 5g f= 2...500Hz (EN-IEC 60068-2-6)

Shock resistance: 30g, 18ms (EN-IEC 60068-2-27)
50g, 11ms (EN-IEC 60068-2-27)

Climate resistance: +25°C-97%RH / +45°C-93%RH (IEC-EN60068-2-30)

IK front protection: IK03

CERTIFICATE

Standards: CSA C22-2, IEC EN 60947-1, IEC EN 60947-5-1, UL508

Approbations: CSA, EAC, UL

Conformities: CE

OTHER


Housing colour: Black

Housing material: Plastic

max. number of switching elements: 6

Short Description: Actuator, Ø 22.3 mm, Ø 40 mm, mushroom-head, non illuminative, Green, Plastic, opaque, round, Black, Plastic, Momentary, IP65, IK03

Mounting cut-outs:

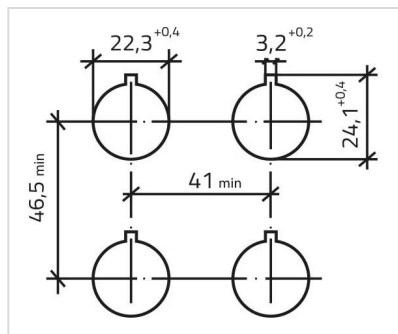

Dimension drawings:

