

Actuator

46-
2736.4920.000



<https://testing.eao.com/p/46-2736.4920.000>

Your product:



46-2736.4920.000
Actuator

FRONT

Front dimension: Ø 40 mm

Front bezel material: Aluminium

Front bezel colour: Silver

Front form: round

MOUNTING

Design: flush

Mounting cut-out: Ø 30.5 mm

OPERATING-/INDICATION PART

Lens illumination: non illuminative

Lens material: Plastic

Lens shape: mushroom-head

Lens optics: opaque

Lens colour: Red

ELECTRICAL CHARACTERISTICS

Protection class: I

MECHANICAL CHARACTERISTIC

Release type: Twist to unlock

Weight: 0.05 kg

Tightening torque: 2 ... 3 Nm (17.7 ... 26.6 Lb-in)

Mechanical lifetime: 50 000 cycles of operation

AMBIENT CONDITION

IK front protection: IK03

Shock resistance: 30g, 18ms (EN-IEC 60068-2-27)
50g, 11ms (EN-IEC 60068-2-27)

Vibration resistance: 5g f= 2...500Hz (EN-IEC 60068-2-6)

IP front protection: IP65

Climate resistance: +25°C-97%RH / +45°C-93%RH (IEC-EN60068-2-30)

Operating temperature: - 25 °C ... + 55 °C

CERTIFICATE

Standards: CSA C22-2, IEC EN 60947-1, IEC EN 60947-5-1, IEC EN 60947-5-5, UL508, UNI EN ISO 12100, UNI EN ISO 13850

Approbations: CSA, UL

Conformities: CE

OTHER

Housing material: Plastic


Short Description: Actuator, Ø 30.5 mm, Ø 40 mm, mushroom-head, non illuminative, Red, Plastic, opaque, round, Silver, Aluminium, IP65, IK03, Twist to unlock

max. number of switching elements: 4

Housing colour: Black

Dimension: Ø 40 mm

Dimension drawings:

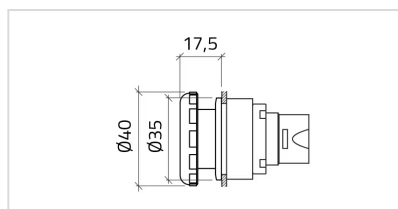

Mounting cut-outs:

