

Actuator

46-

2737.1920.000



<https://testing.eao.com/p/46-2737.1920.000>

Your product:



46-2737.1920.000 Actuator

FRONT

Front bezel material:	Plastic
Front dimension:	Ø 40 mm
Front bezel colour:	Yellow
Front form:	round

MOUNTING

Design:	raised
Mounting cut-out:	Ø 22.3 mm

OPERATING-/INDICATION PART

Lens material:	Plastic
Lens colour:	Red
Lens shape:	mushroom-head
Lens illumination:	non illuminative
Lens optics:	opaque

ELECTRICAL CHARACTERISTICS

Protection class:	II
-------------------	----

MECHANICAL CHARACTERISTIC

Tightening torque:	2 ... 3 Nm (17.7 ... 26.6 Lb-in)
Weight:	0.036 kg

Mechanical lifetime: 50 000 cycles of operation

Release type: Pull unlock

AMBIENT CONDITION

Vibration resistance: 5g f= 2...500Hz (EN-IEC 60068-2-6)

Shock resistance: 30g, 18ms (EN-IEC 60068-2-27)
50g, 11ms (EN-IEC 60068-2-27)

IK front protection: IK03

Operating temperature: – 25 °C ... + 55 °C

IP front protection: IP65

Climate resistance: +25°C-97%RH / +45°C-93%RH (IEC-EN60068-2-30)

CERTIFICATE

Conformities: CE

Approbations: CSA, EAC, UL

Standards: CSA C22-2, IEC EN 60947-1, IEC EN 60947-5-1, IEC EN 60947-5-5, UL508, UNI EN ISO 12100, UNI EN ISO 13850

OTHER

Dimension: Ø 40 mm


Housing material: Plastic

max. number of switching elements: 4

Housing colour: Yellow

Short Description: Actuator, Ø 22.3 mm, Ø 40 mm, mushroom-head, non illuminative, Red, Plastic, opaque, round, Yellow, Plastic, IP65, IK03, Pull unlock

Dimension drawings:

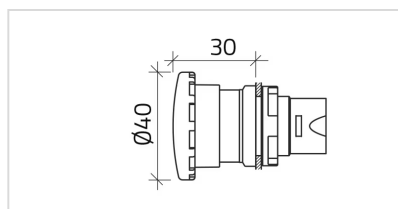

Mounting cut-outs:

