

Actuator

46-
2534.1G40.000



<https://testing.eao.com/p/46-2534.1G40.000>

Your product:



46-2534.1G40.000 Actuator

FRONT

Front bezel colour:	Black
Front form:	round
Front dimension:	Ø 38 mm
Front bezel material:	Plastic

MOUNTING

Design:	raised
Mounting cut-out:	Ø 22.3 mm

OPERATING-/INDICATION PART

Lens illumination:	non illuminative
Lens colour:	Yellow
Lens shape:	mushroom-head
Lens optics:	opaque
Lens material:	Plastic

ELECTRICAL CHARACTERISTICS

Protection class:	II
-------------------	----

MECHANICAL CHARACTERISTIC

Weight:	0.024 kg
Tightening torque:	2 ... 3 Nm (17.7 ... 26.6 Lb-in)

Switching action:	Maintained
Mechanical lifetime:	500 000 cycles of operation

AMBIENT CONDITION


IK front protection:	IK03
Vibration resistance:	5g f= 2...500Hz (EN-IEC 60068-2-6)
Operating temperature:	– 25 °C ... + 55 °C
IP front protection:	IP65
Shock resistance:	30g, 18ms (EN-IEC 60068-2-27) 50g, 11ms (EN-IEC 60068-2-27)
Climate resistance:	+25°C-97%RH / +45°C-93%RH (IEC-EN60068-2-30)

CERTIFICATE

Conformities:	CE
Standards:	CSA C22-2, IEC EN 60947-1, IEC EN 60947-5-1, UL508
Approbations:	CSA, EAC, UL

OTHER

max. number of switching elements:	4
Short Description:	Actuator, Ø 22.3 mm, Ø 38 mm, mushroom-head, non illuminative, Yellow, Plastic, opaque, round, Black, Plastic, Maintained, IP65, IK03
Housing material:	Plastic
Housing colour:	Black
Dimension drawings:	

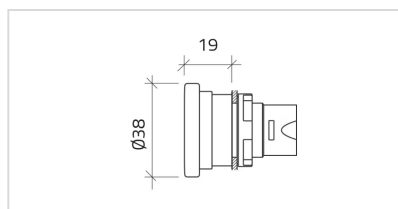

Mounting cut-outs:

