

Actuator

46-
290K.1000.7P8



<https://testing.eao.com/p/46-290K.1000.7P8>

Your product:



46-290K.1000.7P8 Actuator

FRONT

Front form:	round
Front bezel material:	Plastic
Front bezel colour:	Black
Front dimension:	Ø 29 mm

MOUNTING

Mounting cut-out:	Ø 22.3 mm
Design:	raised

ELECTRICAL CHARACTERISTICS

Protection class:	II
-------------------	----

MECHANICAL CHARACTERISTIC

Switching positions:	2 positions
Mechanical lifetime:	50 000 cycles of operation
Switching action:	Rest (a) - Momentary
Switching angle:	60° right
Release type:	Key release to unlock
Tightening torque:	2 ... 3 Nm (17.7 ... 26.6 Lb-in)
Weight:	0.076 kg

AMBIENT CONDITION


Shock resistance:	30g, 18ms (EN-IEC 60068-2-27) 50g, 11ms (EN-IEC 60068-2-27)
Operating temperature:	– 25 °C ... + 55 °C
IK front protection:	IK06
Climate resistance:	+25°C-97%RH / +45°C-93%RH (IEC-EN60068-2-30)
IP front protection:	IP65
Vibration resistance:	5g f= 2...500Hz (EN-IEC 60068-2-6)

CERTIFICATE


Standards:	CSA C22-2, IEC EN 60947-1, IEC EN 60947-5-1, UL508
Conformities:	CE
Approbations:	CSA, EAC, UL

OTHER

Housing material:	Plastic
Short Description:	Actuator, Ø 22.3 mm, Ø 29 mm, round, Black, Plastic, Rest (a) - Momentary, IP65, IK06, Key release to unlock
Housing colour:	Black
max. number of switching elements:	8
Mounting cut-outs:	

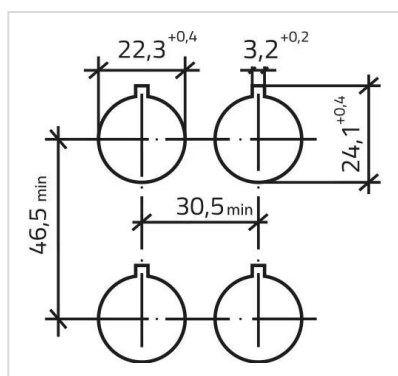

Switching positions:

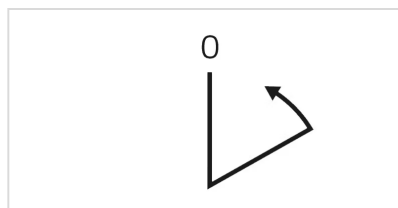

Dimension drawings:

