

Actuator

46-
2C36.1M20.000



<https://testing.eao.com/p/46-2C36.1M20.000>

Your product:



46-2C36.1M20.000 Actuator

FRONT

Front dimension: Ø 32 mm

Front form: round

MOUNTING

Mounting cut-out: Ø 22.3 mm

Design: raised

OPERATING-/INDICATION PART

Lens illumination: non illuminative

Lens colour: Red

Lens optics: opaque

Lens shape: mushroom-head

Lens material: Plastic

ELECTRICAL CHARACTERISTICS

Protection class: II

MECHANICAL CHARACTERISTIC

Weight: 0.034 kg

Release type: Twist to unlock

Tightening torque: 2 ... 3 Nm (17.7 ... 26.6 Lb-in)

Mechanical lifetime: 50 000 cycles of operation

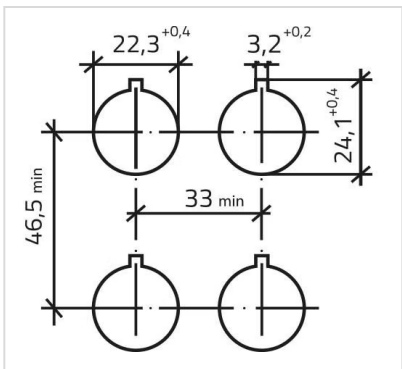
AMBIENT CONDITION

Operating temperature:	- 25 °C ... + 55 °C
IP front protection:	IP65
Vibration resistance:	5g f= 2...500Hz (EN-IEC 60068-2-6)
IK front protection:	IK03
Climate resistance:	+25°C-97%RH / +45°C-93%RH (IEC-EN60068-2-30)
Shock resistance:	30g, 18ms (EN-IEC 60068-2-27) 50g, 11ms (EN-IEC 60068-2-27)

CERTIFICATE

Standards:	CSA C22-2, IEC EN 60947-1, IEC EN 60947-5-1, IEC EN 60947-5-5, UL508, UNI EN ISO 12100, UNI EN ISO 13850
Conformities:	CE
Approbations:	CSA, EAC, UL

OTHER

Short Description:	Actuator, Ø 22.3 mm, Ø 32 mm, mushroom-head, non illuminative, Red, Plastic, opaque, round, IP65, IK03, Twist to unlock
Housing material:	Plastic
max. number of switching elements:	4
Housing colour:	Yellow
Dimension:	Ø 32 mm
Mounting cut-outs:	

Dimension drawings:

