

# Actuator

46-

2J31.15T0.000



<https://testing.eao.com/p/46-2J31.15T0.000>

Your product:

---



## 46-2J31.15T0.000 Actuator

### FRONT

|                       |               |
|-----------------------|---------------|
| Front dimension:      | 58 mm x 29 mm |
| Front bezel colour:   | Black         |
| Front bezel material: | Plastic       |

### MOUNTING

|                   |           |
|-------------------|-----------|
| Design:           | raised    |
| Mounting cut-out: | Ø 22.3 mm |

### OPERATING-/INDICATION PART

|                    |                  |
|--------------------|------------------|
| Lens shape:        | flush            |
| Lens colour:       | Green-red        |
| Lens material:     | Plastic          |
| Lens optics:       | opaque           |
| Lens illumination: | non illuminative |

### ELECTRICAL CHARACTERISTICS

|                   |    |
|-------------------|----|
| Protection class: | II |
|-------------------|----|

### MECHANICAL CHARACTERISTIC

|                      |                                  |
|----------------------|----------------------------------|
| Mechanical lifetime: | 1 Mio. cycles of operation       |
| Weight:              | 0.025 kg                         |
| Tightening torque:   | 2 ... 3 Nm (17.7 ... 26.6 Lb-in) |

**Switching action:** Momentary

## AMBIENT CONDITION

**Climate resistance:** +25°C-97%RH / +45°C-93%RH (IEC-EN60068-2-30)

**Shock resistance:** 30g, 18ms (EN-IEC 60068-2-27)  
50g, 11ms (EN-IEC 60068-2-27)

**IK front protection:** IK03

**Operating temperature:** – 25 °C ... + 55 °C

**Vibration resistance:** 5g f= 2...500Hz (EN-IEC 60068-2-6)

**IP front protection:** IP65

## CERTIFICATE

**Standards:** CSA C22-2, IEC EN 60947-1, IEC EN 60947-5-1, UL508

**Approbations:** CSA, EAC, UL

**Conformities:** CE

## OTHER


**max. number of switching elements:** 8

**Housing colour:** Black

**Housing material:** Plastic

**Short Description:** Actuator, Ø 22.3 mm, 58 mm x 29 mm, flush, non illuminative, Green-red, Plastic, opaque, Black, Plastic, Momentary, IP65, IK03

**Mounting cut-outs:**

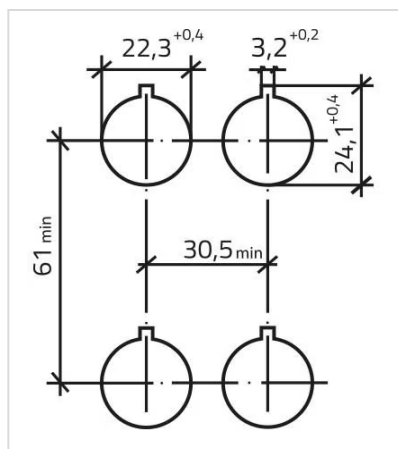

**Dimension drawings:**

