

# Actuator

46-  
2T00.10J0.000



<https://testing.eao.com/p/46-2T00.10J0.000>

Your product:

---



## 46-2T00.10J0.000 Actuator

### FRONT

|                       |         |
|-----------------------|---------|
| Front bezel colour:   | White   |
| Front dimension:      | Ø 29 mm |
| Front form:           | round   |
| Front bezel material: | Plastic |

### MOUNTING

|                   |           |
|-------------------|-----------|
| Mounting cut-out: | Ø 22.3 mm |
| Design:           | raised    |

### OPERATING-/INDICATION PART

|                          |             |
|--------------------------|-------------|
| Illumination colour:     | Blue        |
| Lens cap colour:         | Blue        |
| Lens cap optical effect: | transparent |
| Lens cap material:       | Plastic     |
| Lens cap shape:          | flush       |

### ELECTRICAL CHARACTERISTICS

|                   |    |
|-------------------|----|
| Protection class: | II |
|-------------------|----|

### MECHANICAL CHARACTERISTIC

|                    |                                   |
|--------------------|-----------------------------------|
| Tightening torque: | 1 ... 2.5 Nm (8.8 ... 22.1 Lb-in) |
| Weight:            | 0.009 kg                          |

## AMBIENT CONDITION


|                               |                                                                |
|-------------------------------|----------------------------------------------------------------|
| <b>Climate resistance:</b>    | +25°C-97%RH / +45°C-93%RH (IEC-EN60068-2-30)                   |
| <b>IP front protection:</b>   | IP65                                                           |
| <b>Vibration resistance:</b>  | 5g f= 2...500Hz (EN-IEC 60068-2-6)                             |
| <b>Operating temperature:</b> | – 25 °C ... + 55 °C                                            |
| <b>IK front protection:</b>   | IK03                                                           |
| <b>Shock resistance:</b>      | 30g, 18ms (EN-IEC 60068-2-27)<br>50g, 11ms (EN-IEC 60068-2-27) |

## CERTIFICATE

|                      |                                                    |
|----------------------|----------------------------------------------------|
| <b>Approbations:</b> | CSA, EAC, UL                                       |
| <b>Conformities:</b> | CE                                                 |
| <b>Standards:</b>    | CSA C22-2, IEC EN 60947-1, IEC EN 60947-5-1, UL508 |

## OTHER

|                            |                                                                       |
|----------------------------|-----------------------------------------------------------------------|
| <b>Housing colour:</b>     | White                                                                 |
| <b>Housing material:</b>   | Plastic                                                               |
| <b>Short Description:</b>  | Actuator, Ø 22.3 mm, Ø 29 mm, round, White, Plastic, IP65, IK03, Blue |
| <b>Dimension drawings:</b> |                                                                       |

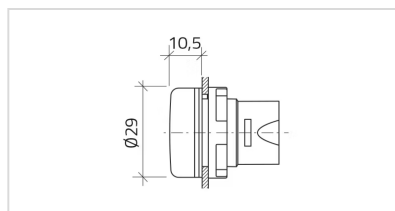

### Mounting cut-outs:

