

Actuator

46-
2W44.3CZ0.001



<https://testing.eao.com/p/46-2W44.3CZ0.001>

Your product:



46-2W44.3CZ0.001 Actuator

FRONT

Front bezel material:	Metal
Front bezel colour:	Silver
Front form:	round
Front dimension:	Ø 30 mm

MOUNTING

Design:	raised
Mounting cut-out:	Ø 22.3 mm

OPERATING-/INDICATION PART

Lever bar colour:	Black
Lever shape:	short
Lever colour:	Yellow
Lever material:	plastic

ELECTRICAL CHARACTERISTICS

Protection class:	II
-------------------	----

MECHANICAL CHARACTERISTIC

Switching action:	Maintained - Momentary
Mechanical lifetime:	1 Mio. cycles of operation
Switching angle:	90°

Switching positions:	2 positions
Tightening torque:	2 ... 3 Nm (17.7 ... 26.6 Lb-in)
Weight:	0.038 kg

AMBIENT CONDITION


Shock resistance:	30g, 18ms (EN-IEC 60068-2-27) 50g, 11ms (EN-IEC 60068-2-27)
IK front protection:	IK03
Operating temperature:	– 25 °C ... + 55 °C
Vibration resistance:	5g f= 2...500Hz (EN-IEC 60068-2-6)
IP front protection:	IP65
Climate resistance:	+25°C-97%RH / +45°C-93%RH (IEC-EN60068-2-30)

CERTIFICATE

Standards:	CSA C22-2, IEC EN 60947-1, IEC EN 60947-5-1, UL508
Conformities:	CE

OTHER

Short Description:	Actuator, Ø 22.3 mm, Ø 30 mm, illuminative, Yellow, short, round, Silver, Metal, Maintained - Momentary, IP65, IK03
max. number of switching elements:	2
Housing material:	Plastic
Housing colour:	Black
Switching positions:	

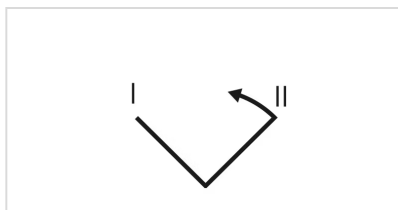

Dimension drawings:

