

# Actuator

46-  
2W44.3CM0.001



<https://testing.eao.com/p/46-2W44.3CM0.001>

Your product:

---



## 46-2W44.3CM0.001 Actuator

### FRONT

|                       |         |
|-----------------------|---------|
| Front form:           | round   |
| Front bezel colour:   | Silver  |
| Front dimension:      | Ø 30 mm |
| Front bezel material: | Metal   |

### MOUNTING

|                   |           |
|-------------------|-----------|
| Design:           | raised    |
| Mounting cut-out: | Ø 22.3 mm |

### OPERATING-/INDICATION PART

|                   |         |
|-------------------|---------|
| Lever colour:     | Green   |
| Lever shape:      | short   |
| Lever material:   | plastic |
| Lever bar colour: | White   |

### ELECTRICAL CHARACTERISTICS

|                   |    |
|-------------------|----|
| Protection class: | II |
|-------------------|----|

### MECHANICAL CHARACTERISTIC

|                      |                                  |
|----------------------|----------------------------------|
| Tightening torque:   | 2 ... 3 Nm (17.7 ... 26.6 Lb-in) |
| Switching positions: | 2 positions                      |
| Switching angle:     | 90°                              |

|                             |                            |
|-----------------------------|----------------------------|
| <b>Mechanical lifetime:</b> | 1 Mio. cycles of operation |
| <b>Switching action:</b>    | Maintained - Momentary     |
| <b>Weight:</b>              | 0.038 kg                   |

## AMBIENT CONDITION


|                               |                                                                |
|-------------------------------|----------------------------------------------------------------|
| <b>IP front protection:</b>   | IP65                                                           |
| <b>Operating temperature:</b> | – 25 °C ... + 55 °C                                            |
| <b>Vibration resistance:</b>  | 5g f= 2...500Hz (EN-IEC 60068-2-6)                             |
| <b>Shock resistance:</b>      | 30g, 18ms (EN-IEC 60068-2-27)<br>50g, 11ms (EN-IEC 60068-2-27) |
| <b>IK front protection:</b>   | IK03                                                           |
| <b>Climate resistance:</b>    | +25°C-97%RH / +45°C-93%RH (IEC-EN60068-2-30)                   |

## CERTIFICATE

|                      |                                                    |
|----------------------|----------------------------------------------------|
| <b>Conformities:</b> | CE                                                 |
| <b>Standards:</b>    | CSA C22-2, IEC EN 60947-1, IEC EN 60947-5-1, UL508 |

## OTHER

|                                           |                                                                                                                    |
|-------------------------------------------|--------------------------------------------------------------------------------------------------------------------|
| <b>Short Description:</b>                 | Actuator, Ø 22.3 mm, Ø 30 mm, illuminative, Green, short, round, Silver, Metal, Maintained - Momentary, IP65, IK03 |
| <b>max. number of switching elements:</b> | 2                                                                                                                  |
| <b>Housing material:</b>                  | Plastic                                                                                                            |
| <b>Housing colour:</b>                    | Black                                                                                                              |
| <b>Dimension drawings:</b>                |                                                                                                                    |

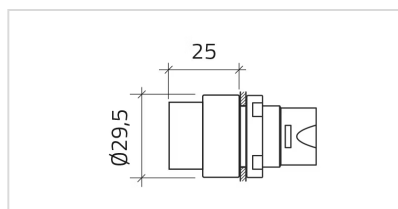

|                             |  |
|-----------------------------|--|
| <b>Switching positions:</b> |  |
|-----------------------------|--|

