


Float level switch ERH-01-18

- ✓ Min/max signalization
- ✓ Range change possible by changing weight position
- ✓ Direct control of low power pumps
- ✓ Chemical resistance to most common media
- ✓ High mechanical and electrical resistance

Technical data

Minimal signalization range	350mm ±15%
Max. medium temperature	85°C
Max. pressure	0,35 MPa
Nominal current I _{nc}	20 A
Power supply	250V AC-50/60Hz
Contacts	filling - black – blue emptying - black – brown
Ambient temperature	-25...+80 °C
Ingress protection class	IP68
Cable length	10 or 20 m
Cable type	Neoprene HR HY H07RN8-F 3x1mm ²
Float material	Copolymer polypropylene
Additional accessories	Weight

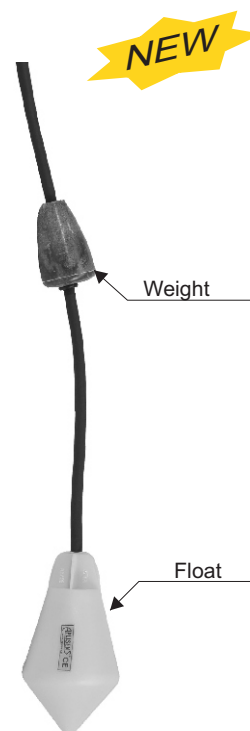

Ordering procedure

ERH-01-18 / L = ... m/...

Cable length

Optional: weight