


Multimode Duplex OM4 50/125 Fiber Optic Cable, LC/LC, 3 m

CFO-MDOM4-LC/LC-3M

- OM4 multimode patch cables ensure optimal performance in 10/40/100G networking applications

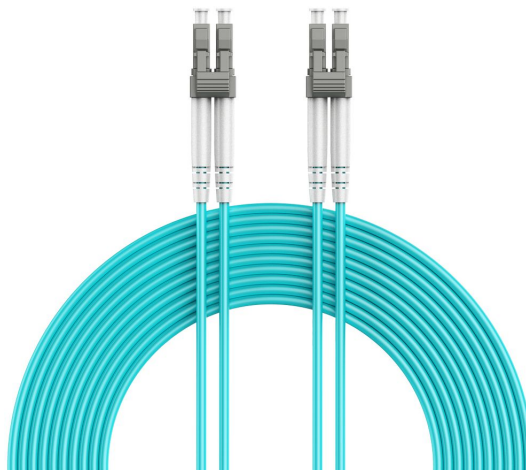

Features

- Duplex multimode fibre optic cable (50/125 OM4)
- Supports data transfer rates up to 100 Gbps
- Perfect for high speed data transfer with minimum signal loss
- Integrated LC/LC-connectors for an easy and reliable connection

Packaging

Q'ty in crtn, pcs	200
Crtn volume, CUM	0.059
Crtn weight, kgs	9.75
Individual package size LxWxH:	195x130x20 mm
Carton size LxWxH:	495x365x325 mm
Country of origin	CN
Barcode	8716309131490
Customs code	8544429090

Specifications

Type: OM4 Duplex Multimode
 Fibre: 50/125 μ m
 Connector 1: LC UPC (m)
 Connector 2: LC UPC (m)
 Insertion loss: $\approx$ 0.3 dB
 Return loss: $\approx$ 20 dB
 Wavelength: 850/1300 nm
 Attenuation at 850 nm: 3.0 dB/km
 Attenuation at 1300 nm: 1.0 dB/km
 Network Compatibility: 1 Gbps (Gigabit); 10 Gbps; 25 Gbps; 40 Gbps; 100 Gbps
 Insert-pull test (1000 times) $<$ 0.3 dB
 Fire Rating: LSZH
 Operating Temperature -20°C to 60°C
 Cable length: 3 m

Certificates

