

BULLETS & RECEPTACLES (PC・PCE TYPE)

SPECIFICATION

■ MATERIAL : Terminal : Brass (Electro-tin-plated)
Sleeve : Oxygen free copper tube
(electro-tin-plated)

Insulator : Nylon

■ RATED VOLTAGE : 300V

■ PC TYPE

RoHS 10

See page 2




■ RATED CURRENT : See following table

Wire mm ²	0.5	0.75	1.25	2
A	10	12	15	20

■ INSULATOR TEMPERATURE : - 40℃~+ 105℃

■ FLAME RETARDANCE : UL94V2

■ APPLICABLE WIRE : Performance ratings
comply with JIS standards wire(IV・KIV・VSF)

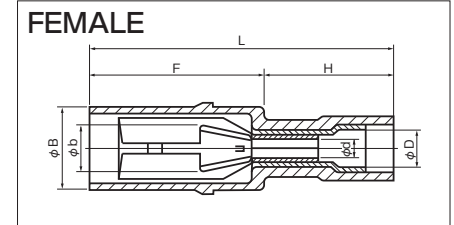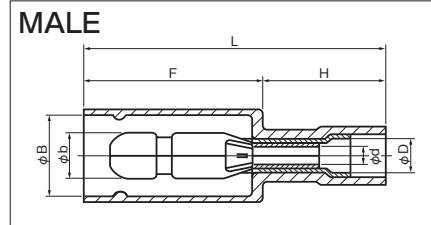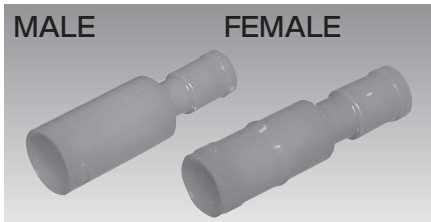

PART NUMBER	DIMENSIONS mm							WIRE RANGE		TOOL No.		INS	STD COLOR	STD QTY/BOX
	ϕb	ϕB	ϕd	ϕD	L	F	H	STRANDED mm²	AWG	HAND TOOL No.				
										TOOL BODY No.	DIES No.			
PC 2005-M	2.0	5.1	1.7	3.1	26.5	15.0	11.5	0.5 ⌋ 0.75	20-18	NH 5 NH 32 NA 10 NA 3		Nylon	TRANSLUCENT	1,000 (100×10)
PC 2005-F	2.0	4.7			24.5	13.0				N10 10 N3 5				
PC 4009-M	4.0	7.4	1.8	3.2	27.7	16.5	11.2	0.75 ⌋ 1.25	18-16	NH 11 NH 32 NA 10 NA 3			RED TRANSLUCENT	1,000 (100×10)
PC 4009-F	3.9	6.9			26.2	15.0				N10 11 N3 11				
PC 4020-M	4.0	7.4	2.4	3.9	27.7	16.5		2.0	14	NH 12 NH 32 NA 10 NA 3			BLUE TRANSLUCENT	1,000 (100×10)
PC 4020-F	3.9	6.9			26.2	15.0				N10 12 N3 12				

No insulator lock on PC2005.

