


Sockets

BIL 30 Au

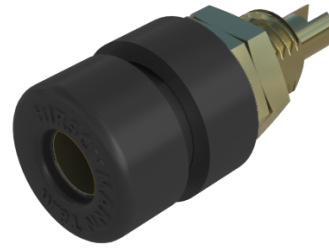

Product	BIL 30 Au
description	Socket with insulated head and ring for installation in equipment chassis and switchpanels up to 4 mm wall thickness. 4 mm diameter gold-plated zinc die-cast socket, with solder connection.
operating instruction	BA403
article-no. / *colour	9301667xx  00 black  01 red  02 blue  03 yellow  04 green  05 brown  06 gray  07 white  09 violet Au
drawing	
technical data	
connection	M6 thread, solder connection
rated voltage	30 VAC / 60 VDC
measurement cat. acc. to IEC 61010	O ⁽²⁾
rated current (consider derating curve)	32 A
material socket	SKS_ZINKDRUCKGUSS-VERZINNT
housing material	PA
temperature range acc. To IEC61010 ⁽¹⁾	-25 °C to +85 °C
flammability class acc. to UL 94 (only valid for basic material of housing)	V-2

⁽¹⁾ contact the manufacturer for applications at deviating temperature ranges

⁽²⁾ without rated measurement category, for other circuits that are not directly connected to mains
stand: 24.08.2022

stand: 24.08.2022

4 mm system