


Sockets

MPK 1

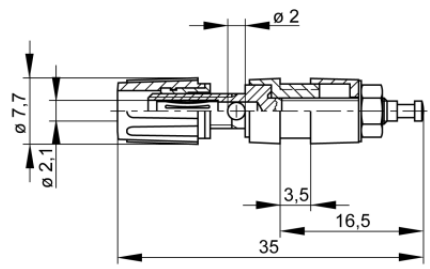

Product	MPK 1
description	2 mm diameter miniature pole clamp with transverse hole, insulated, goldplated copper beryllium contact spring, tin-plated brass threaded bolt with solder connection. Suitable for installation in equipment chassis and switch panels up to a maximum wall thickness of 3.5 mm.
operating instruction	BA203
article-no. / *colour	● 00 black ● 01 red Au
drawing	
technical data	
connection	solder connection
rated voltage	30 VAC / 60 VDC
measurement cat. acc. to IEC 61010	O ⁽²⁾
rated current (consider derating curve)	6 A
material socket	brass, gold plated
housing material	PA
temperature range acc. To IEC61010 ⁽¹⁾	-20 °C to +60 °C

⁽¹⁾ contact the manufacturer for applications at deviating temperature ranges

⁽²⁾ without rated measurement category, for other circuits that are not directly connected to mains

stand: 21.06.2022

stand: 21.06.2022