


Sockets

MBI 1

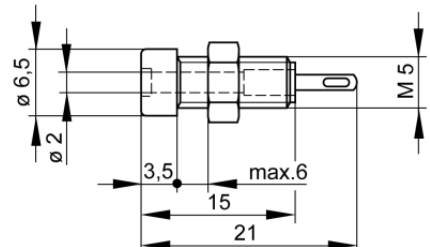

Product	MBI 1
description	2 mm diameter miniature socket, insulated, tin-plated copper beryllium contact (spring-loaded), with solder connection. Suitable for installation in equipment chassis and switch panels up to a maximum wall thickness of 5 mm.
operating instruction	BA205
article-no. / *colour	9303081xx  00 black  01 red  02 blue  03 yellow  04 green  06 gray
drawing	
technical data	
connection	solder connection
rated voltage	30 VAC / 60 VDC
measurement cat. acc. to IEC 61010	O ⁽²⁾
rated current (consider derating curve)	6 A
material socket	contact spring: copper - beryllium
housing material	PA
temperature range acc. To IEC61010 ⁽¹⁾	-20 °C to +60 °C

⁽¹⁾ contact the manufacturer for applications at deviating temperature ranges

⁽²⁾ without rated measurement category, for other circuits that are not directly connected to mains

stand: 21.06.2022

stand: 21.06.2022