


Crocodile clips

MA 1 Crimp

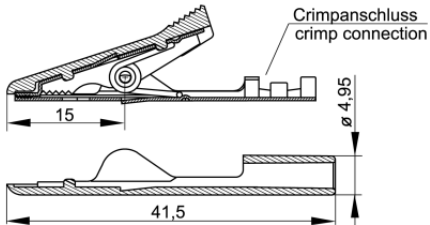

Product	MA 1 Crimp
description	Miniature alligator clip with high strength insulation and nickel-plated brass / bronze jaws. The flat part of the chuck jaws (fine wire section) allows a secure contacting, when thin wires be pinched. It is possible to clamp of flat components (soldering eyes) and wires up to a maximum diameter of 4mm. Crimp connection for 0,25mm ² up to 0,5mm ² wiring, with following assembly of the bottom insulating part (shim). With suitable tool to crimp (for example with TE use 539680 - 2).
operating instruction	BA210
article-no. / *colour	9303181xx 00 black 01 red 02 blue 03 yellow 04 green 06 gray 07 white Ni
drawing	
	
technical data	
connection	Crimp terminal 0.25 mm ² up to 0.5 mm ²
rated voltage	30 VAC / 60 VDC
measurement cat. acc. to IEC 61010	O ⁽²⁾
rated current (consider derating curve)	8 A
material socket	bronze, nickel plated
housing material	PP
temperature range acc. To IEC61010 ⁽¹⁾	-25 °C to +100 °C
flammability class acc. to UL 94 (only valid for basic material of housing)	HB

2 mm system

clamping range	4 mm
----------------	------

⁽¹⁾ contact the manufacturer for applications at deviating temperature ranges

⁽²⁾ without rated measurement category, for other circuits that are not directly connected to mains

stand: 21.06.2022

stand: 21.06.2022