


Crocodile clips

MA 2 VA

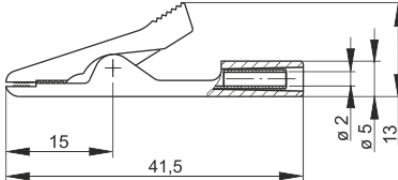

Product	MA 2 VA
description	Miniature alligator clip with high strength insulation and 2 mm socket connection. Jaws and spring in stainless steel. The flat part of the jaws (fine wire section) allows a secure contact to be made when clamping even the thinnest wires. Capable of clamping flat components (soldering eyes) and wires up to a maximum diameter of 4 mm.
operating instruction	BA210
article-no. / *colour	9303191xx  00 black  01 red  02 blue  03 yellow  04 green  05 brown  06 gray  07 white
drawing	
	
technical data	
connection	2 mm socket
rated voltage	30 VAC / 60 VDC
rated current (consider derating curve)	6 A
material socket	stainless steel
housing material	PP
temperature range acc. To IEC61010 ⁽¹⁾	-25 °C to 70 °C
flammability class acc. to UL 94 (only valid for basic material of housing)	HB
clamping range	4 mm

⁽¹⁾ contact the manufacturer for applications at deviating temperature ranges
stand: 25.06.2024

stand: 25.06.2024

2 mm system