


Sockets

BIL 20

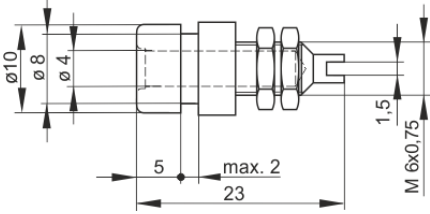

Product	BIL 20
description	Socket with insulated head and ring for installation in equipment chassis and switchpanels with a wall thickness up to 2 mm. 4 mm diameter tin-plated zinc die-cast socket, with solder Connection and M6 thread.
operating instruction	BA403
article-no. / *colour	9301761xx  00 black  01 red  02 blue  03 yellow  04 green  05 brown  06 gray  07 white  09 violet Sn
drawing	
	
technical data	
connection	M6 thread, solder connection
rated voltage	30 VAC / 60 VDC
measurement cat. acc. to IEC 61010	O ⁽²⁾
rated current (consider derating curve)	32 A
material socket	SKS_ZINKDRUCKGUSS-VERZINNT
housing material	PA
temperature range acc. To IEC61010 ⁽¹⁾	-25 °C to +85 °C
flammability class acc. to UL 94 (only valid for basic material of housing)	V-2

⁽¹⁾ contact the manufacturer for applications at deviating temperature ranges

⁽²⁾ without rated measurement category, for other circuits that are not directly connected to mains

stand: 24.08.2022

stand: 24.08.2022

4 mm system