


Sockets

PK 10 A

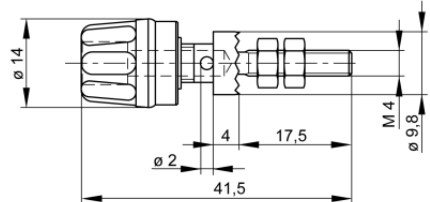

Product	PK 10 A
description	Pole terminal with claw edge and captive insulated head. 4 mm diameter nickel-plated brass threaded bolt with 2 mm diameter transverse hole. For installation in equipment chassis and switch panels.
operating instruction	BA403
article-no. / *colour	9300991xx  00 black  01 red  02 blue  03 yellow  04 green  05 brown  06 gray  07 white  09 violet  88 yellow green Ni
drawing	
technical data	
connection	M4 thread
rated voltage	30 VAC / 60 VDC
measurement cat. acc. to IEC 61010	O ⁽²⁾
rated current (consider derating curve)	16 A
material socket	brass, nickel plated
housing material	PA
temperature range acc. To IEC61010 ⁽¹⁾	-25 °C to +100 °C

⁽¹⁾ contact the manufacturer for applications at deviating temperature ranges

⁽²⁾ without rated measurement category, for other circuits that are not directly connected to mains

stand: 21.06.2022

stand: 21.06.2022