


Plugs

KB 2

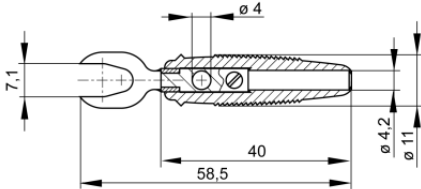

Product	KB 2
description	Cable lug with shatter-proof, flexible insulated sleeve with 4 mm diameter transverse hole. Screw connection up to a maximum of 1.5 mm ² . For connection to bolts from 4 mm to 7 mm diameter. Nickel-plated brass contact material.
operating instruction	BA410
article-no. / *colour	9305841xx ● 00 black ● 01 red ● 02 blue ● 03 yellow ● 04 green Ni
drawing	
	
technical data	
connection	screw terminal
rated voltage	30 VAC / 60 VDC
measurement cat. acc. to IEC 61010	O ⁽²⁾
rated current (consider derating curve)	30 A
material plug	brass, nickel plated
housing material	PVC-P
temperature range acc. To IEC61010 ⁽¹⁾	-25 °C to +70 °C
flammability class acc. to UL 94 (only valid for basic material of housing)	HB

⁽¹⁾ contact the manufacturer for applications at deviating temperature ranges

⁽²⁾ without rated measurement category, for other circuits that are not directly connected to mains

stand: 21.06.2022

stand: 21.06.2022