


Sockets

BU 20

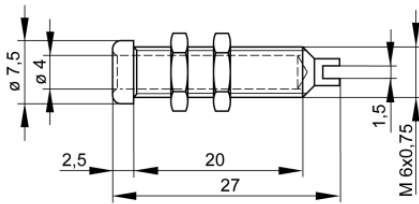

Product	BU 20	
description	Bright metal 4 mm diameter nickel-plated brass socket with solder connection and M6 thread. For installation in equipment chassis and switch panels till 13.5 mm wall thickness.	
operating instruction	BA403	
Articlenummer	930177000	
		Ni
drawing		
		
technical data		
connection	M6 thread, solder connection	
rated voltage	30 VAC / 60 VDC	
measurement cat. acc. to IEC 61010	O ⁽²⁾	
rated current (consider derating curve)	16 A	
material socket	brass, nickel plated	
temperature range acc. To IEC61010 ⁽¹⁾	-25 °C to +100 °C	

⁽¹⁾ contact the manufacturer for applications at deviating temperature ranges

⁽²⁾ without rated measurement category, for other circuits that are not directly connected to mains

stand: 21.06.2022

stand: 21.06.2022

4 mm system