


Sockets

KUN 30 Au

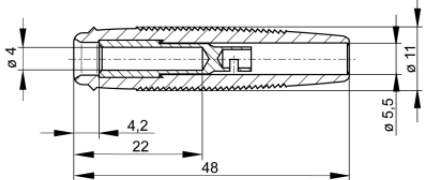

Product	KUN 30 Au
description	Shatter-proof, flexible, insulated coupling for a 4 mm diameter plug and solder connection up to a cable cross-section of 2.5 mm ² . Gold-plated brass socket.
operating instruction	BA405
article-no. / *colour	9318047xx  00 black  01 red  02 blue  03 yellow  04 green  07 white Au
drawing	
	
technical data	
connection	solder connection
rated voltage	30 VAC / 60 VDC
rated current (consider derating curve)	16 A
material socket	brass, gold plated
housing material	PVC-P
temperature range acc. To IEC61010 ⁽¹⁾	-25 °C to +70 °C

⁽¹⁾ contact the manufacturer for applications at deviating temperature ranges
stand: 26.07.2023

stand: 26.07.2023

4 mm system