


Plugs

LAS S WS

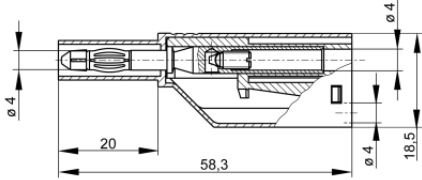

Product	LAS S WS
description	Safety connector for tower construction with screw connection for leads from 0.5 mm ² to 1.5 mm ² , outer diameter of lead max. 4.2 mm. Plug 4 mm with caged spring, rigid socket 4 mm, 1000 V-system. Simple assembly by "Click-System".
operating instruction	BA461
article-no. / *colour	9340991xx  00 black  01 red  02 blue  03 yellow  04 green  05 brown  06 gray  07 white  09 violet Ni
drawing	
	
technical data	
connection	screw terminal
rated voltage	AC/DC 1000 V
measurement cat. acc. to IEC 61010	CAT II
rated current (consider derating curve)	24 A
material plug	brass, nickel plated
housing material	PA
temperature range acc. To IEC61010 ⁽¹⁾	-15 °C to +70 °C
flammability class acc. to UL 94 (only valid for basic material of housing)	V-2
UL	cURus E537895

⁽¹⁾ contact the manufacturer for applications at deviating temperature ranges

stand: 22.08.2024

stand: 22.08.2024