
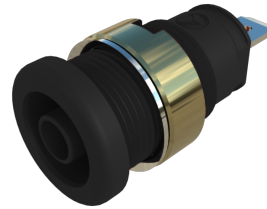


Sockets

SEB 2610 F4,8

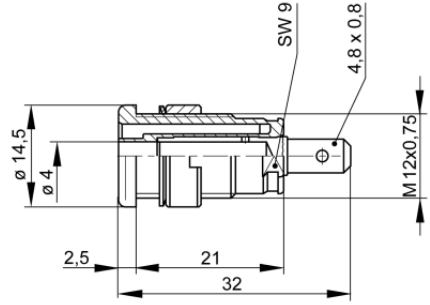

Product	SEB 2610 F4,8
description	Safety built-in socket, 4 mm diameter, contact-protected, with 4.8 x 0.8 tab connector complying with DIN 46 244, gold-plated brass. For installation into switchpanels and equipment chassis with wall thicknesses up to 6 mm. Installation hole: 12.2 mm diameter, Tightening torque: 50 Ncm, Accessory: assembly tool MW SEB
operating instruction	BA451
article-no. / *colour	9723551xx  00 black 01 red 02 blue 03 yellow 04 green 05 brown 06 gray 07 white 09 violet 88 yellow green 
drawing	
	
technical data	
connection	flat connector 4.8 x 0.8 mm
rated voltage	AC/DC 1000 V
measurement cat. acc. to IEC 61010	CAT III
rated current (consider derating curve)	25 A
material socket	brass, gold plated
housing material	PA
temperature range acc. To IEC61010 ⁽¹⁾	-40 °C to +80 °C

4 mm safety system

inflammability class acc. to UL 94 (only valid for basic material of housing)	V-2
UL	cURus E537895

⁽¹⁾ contact the manufacturer for applications at deviating temperature ranges
 stand: 14.08.2024

stand: 14.08.2024