


Sockets

SEB 2600 G M4

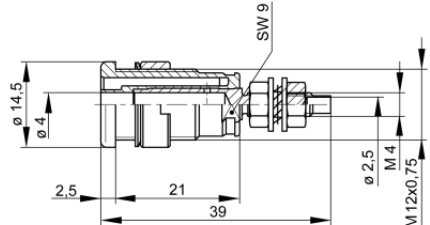

Product	SEB 2600 G M4
description	Safety built-in socket, 4 mm diameter, touch-protected, M 4 thread and solder connection, gold-plated brass. For installation into switch panels and equipment chassis with wall thicknesses up to 6 mm. Installation hole: 12.2 mm diameter, Tightening torque: 50 Ncm Accessory: assembly tool MW SEB
operating instruction	BA451
article-no. / *colour	9723541xx ● 00 black ● 01 red ● 02 blue ● 03 yellow ● 04 green ● 05 brown ● 06 gray ● 07 white ● 09 violet ● 88 yellow green Au
drawing	
	
technical data	
connection	M4 thread, solder connection
rated voltage	AC/DC 1000 V
measurement cat. acc. to IEC 61010	CAT III
rated current (consider derating curve)	32 A
material socket	brass, gold plated
housing material	PA
temperature range acc. To IEC61010 ⁽¹⁾	-40 °C to +80 °C
flammability class acc. to UL 94 (only valid for basic material of housing)	V-2

4 mm safety system

UL	cURus E537895
----	---------------

⁽¹⁾ contact the manufacturer for applications at deviating temperature ranges
stand: 22.08.2024

stand: 22.08.2024