


Measuring leads

MVL 2/100

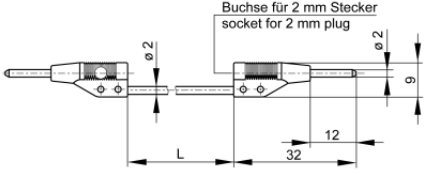

Product	MVL 2/100
description	Injection-moulded measuring lead, at either end 2 mm diameter nickel-plated brass connector and 2 mm diameter socket with contact spring, for tower constructions. Highly flexible stranded lead 0.5 mm ² , grip and lead shatter-proof.
operating instruction	BA201
article-no. / *colour	● 00 black ● 01 red
drawing	
	
technical data	
rated voltage	30 VAC / 60 VDC
measurement cat. acc. to IEC 61010	O ⁽²⁾
rated current (consider derating curve)	6 A
material socket	contact pin: brass contact spring: copper - beryllium
housing material	PP
temperature range acc. To IEC61010 ⁽¹⁾	-40 °C to +60 °C
flammability class acc. to UL 94 (only valid for basic material of housing)	HB
cable length	100 cm
conductor size	0,5 mm ²
cable material	PVC

⁽¹⁾ contact the manufacturer for applications at deviating temperature ranges

⁽²⁾ without rated measurement category, for other circuits that are not directly connected to mains
stand: 21.06.2022

stand: 21.06.2022