
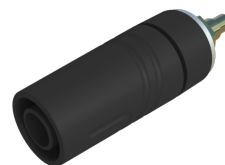


Sockets

SAB 2640 LK Au

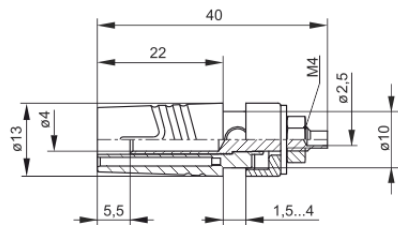

Product	SAB 2640 LK Au
description	Safety surface-mounted socket, 4 mm diameter, contact-protected, gold-plated brass with solder connection. For installation into switch-panels and equipment-chassis of 1-4mm thickness. Connects with safety test leads.
operating instruction	BA456
article-no. / *colour	9723587xx 00 black 01 red 02 blue 03 yellow 04 green 05 brown 06 gray 07 white 09 violet Au
drawing	
	
technical data	
connection	solder connection
rated voltage	AC/DC 1000 V
measurement cat. acc. to IEC 61010	CAT II
rated current (consider derating curve)	32 A
material socket	brass, gold plated
housing material	PA
temperature range acc. To IEC61010 ⁽¹⁾	-25°C °C to +70 °C
flammability class acc. to UL 94 (only valid for basic material of housing)	V-2

⁽¹⁾ contact the manufacturer for applications at deviating temperature ranges
 stand: 21.06.2022

stand: 21.06.2022