


Plugs

LAS 30

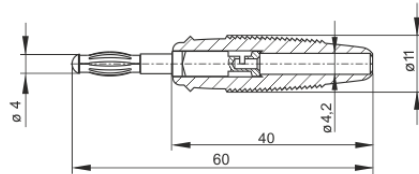

Product	LAS 30
description	Laminated, shatter-proof plug with caged spring and tapering sleeve providing protection against kinking. Soldered connections up to 1.5mm ² , cable diameters up to 4.2mm. Nickel-plated brass contact, nickel-plated copper beryllium contact spring.
operating instruction	BA409
article-no. / *colour	9725181xx ● 00 black ● 01 red ● 02 blue ● 03 yellow ● 04 green
drawing	
technical data	
connection	solder connection
rated voltage	30 VAC / 60 VDC
measurement cat. acc. to IEC 61010	O ⁽²⁾
rated current (consider derating curve)	32 A
material socket	contact pin: brass contact spring: copper - beryllium
housing material	PVC-P
temperature range acc. To IEC61010 ⁽¹⁾	-25 °C to +70 °C

⁽¹⁾ contact the manufacturer for applications at deviating temperature ranges

⁽²⁾ without rated measurement category, for other circuits that are not directly connected to mains
stand: 21.06.2022

stand: 21.06.2022

4 mm system