


## Clamp-type test probe

### KLEPS FP 2B

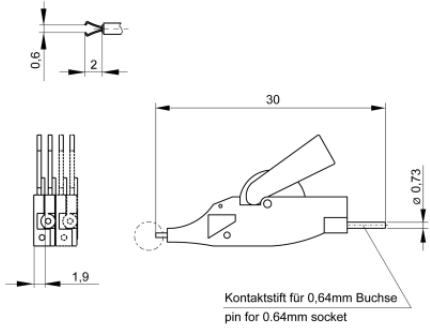

| Product                  | KLEPS FP 2B                                                                                                                                                                                                                                                |
|--------------------------|------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------|
| description              | Makes it possible to contact QFPIC s from 0.5 to 0.8 mm lead pitch. Supplied in pairs (yellow and green). The slim build of the clip make it possible to test QFPIC s with several clips simultaneously. Can be plugged with MKL- and MAL measuring leads. |
| operating instruction    | BA002                                                                                                                                                                                                                                                      |
| article-no. /<br>*colour | 9741011xx<br><br><br>88<br>yellow<br>green                                                                                                                              |
| drawing                  |                                                                                                                                                                                                                                                            |
|                          |                                                                                                                                                                        |
| technical data           |                                                                                                                                                                                                                                                            |
| connection               | 2 x unsprung pin Ø 0.73 mm                                                                                                                                                                                                                                 |
| rated voltage            | 30 VAC / 60 VDC                                                                                                                                                                                                                                            |
| material socket          | spring steel                                                                                                                                                                                                                                               |
| housing material         | ABS                                                                                                                                                                                                                                                        |
| clamp type               | Micro grip jaws                                                                                                                                                                                                                                            |
| clamping range           | 0,5 mm – 0,8 mm                                                                                                                                                                                                                                            |

stand: 10.01.2019

stand: 10.01.2019

0.64 mm system