


Plugs

MST S WS 30 Au

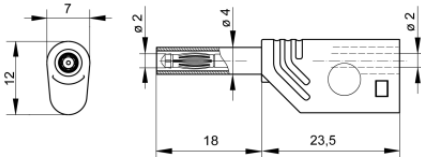

Product	MST S WS 30 Au
description	Safety stackable plug with solder connection for leads from 0.5 mm ² to 1.0 mm ² . Outer diameter of lead max. 2.9 mm. Spring loaded plug and unsprung 2 mm socket for onward connection capability, 1000 V-system, IEC 61010. Simple assembly by "Click-System".
operating instruction	BA255
article-no. / *colour	9750907xx  00 black  01 red  02 blue  03 yellow  04 green  05 brown  06 gray  07 white  09 violet Au
drawing	
	
technical data	
connection	solder connection
rated voltage	AC/DC 1000 V
measurement cat. acc. to IEC 61010	CAT III
rated current (consider derating curve)	10 A
material plug	brass, gold plated
housing material	PA
temperature range acc. To IEC61010 ⁽¹⁾	-25 °C to +70 °C
flammability class acc. to UL 94 (only valid for basic material of housing)	V-2

⁽¹⁾ contact the manufacturer for applications at deviating temperature ranges
stand: 21.06.2022

stand: 21.06.2022