


Sockets

MSEB 2630 S 1,9 Au

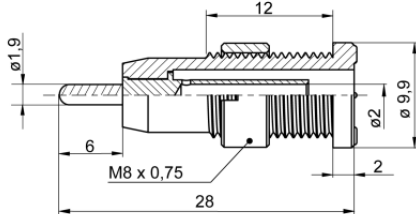

Product	MSEB 2630 S 1,9 Au
description	Miniature - safety built-in socket, 2 mm diameter, touch protected, 1,9mm soldering spike connection, gold-plated brass. For installation into switch- panels and equipment chassis with a wall thickness up to 8mm. Installation hole: 8mm diameter
operating instruction	BA254
article-no. / *colour	9754597xx 00 black 01 red 02 blue 03 yellow 04 green 05 brown 06 gray 07 white 09 violet 88 yellow green Au
drawing	
	
technical data	
connection	solder connection
rated voltage	AC/DC 1000 V
measurement cat. acc. to IEC 61010	CAT III
rated current (consider derating curve)	10 A
material socket	brass, gold plated
housing material	PA
temperature range acc. To IEC61010 ⁽¹⁾	-25 °C to +70 °C
flammability class acc. to UL 94 (only valid for basic material of housing)	V-2

2 mm safety system

UL	cURus E537895
----	---------------

⁽¹⁾ contact the manufacturer for applications at deviating temperature ranges
stand: 22.08.2024

stand: 22.08.2024