


Earthing Braided Copper Strap

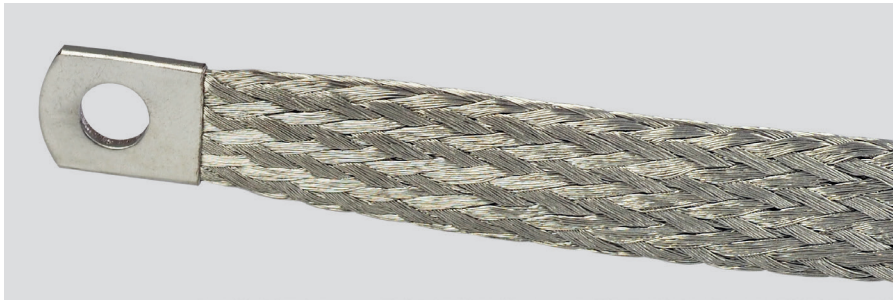

Earthing Braided Copper Strap

- for EMC applications (interferences elimination)
- rounded contacts

Technical Data

- temperature range: -20°C up to + 125°C
- single wire diameter: 0,2 mm
- resistant to cyclic bends
- seamlessly pressed contacts

Material


- tinned copper
- tinned copper contacts

Application:

- automotive industry
- railway industry
- energy sector, robotics
- control cabinets, switchgear rooms and switchgears
- control panel elements
- movable connections of electrical devices working in direct and alternating current circuits

Note

- earthing braided strips with other lengths, hole diameters and contacts, made of tinned and non-tinned copper 0,1 mm diameter single wire
- packaging as requested

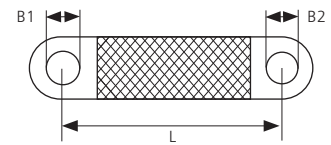

Part no.	Type	Cross-section mm ²	Length L mm	ØB1 mm	ØB2 mm	Unit
18052692	HELU-MB-CUV 6-100-4,5/4,5-R	6	100	4,5	4,5	1
18052693	HELU-MB-CUV 6-200-4,5/4,5-R	6	200	4,5	4,5	1
11008412	HELU-MB-CUV 6-150-4,5/6,5-R	6	150	4,5	6,5	1
18049226	HELU-MB-CUV 6-400-6,5/6,5-R	6	400	6,5	6,5	1
11008411	HELU-MB-CUV 6-500-6,5/6,5-R	6	500	6,5	6,5	1
18051580	HELU-MB-CUV 10-100-6,5/6,5-R	10	100	6,5	6,5	1
11008421	HELU-MB-CUV 10-200-6,5/6,5-R	10	200	6,5	6,5	1
11008422	HELU-MB-CUV 10-200-8,5/8,5-R	10	200	8,5	8,5	1
11008423	HELU-MB-CUV 10-300-6,5/6,5-R	10	300	6,5	6,5	1
11008424	HELU-MB-CUV 10-300-8,5/8,5-R	10	300	8,5	8,5	1
11008425	HELU-MB-CUV 10-400-8,5/8,5-R	10	400	8,5	8,5	1
18049207	HELU-MB-CUV 10-500-6,5/6,5-R	10	500	6,5	6,5	1
11008442	HELU-MB-CUV 16-100-8,5/8,5-R	16	100	8,5	8,5	1
11008443	HELU-MB-CUV 16-200-6,5/6,5-R	16	200	6,5	6,5	1
11008445	HELU-MB-CUV 16-200-6,5/8,5-R	16	200	6,5	8,5	1
11008378	HELU-MB-CUV 16-200-8,5/8,5-R	16	200	8,5	8,5	1
11008446	HELU-MB-CUV 16-250-6,5/8,5-R	16	250	6,5	8,5	1
11008444	HELU-MB-CUV 16-300-6,5/6,5-R	16	300	6,5	6,5	1
11008447	HELU-MB-CUV 16-300-6,5/8,5-R	16	300	6,5	8,5	1
11008379	HELU-MB-CUV 16-300-8,5/8,5-R	16	300	8,5	8,5	1
18049232	HELU-MB-CUV 16-400-6,5/6,5-R	16	400	6,5	6,5	1
18049233	HELU-MB-CUV 16-450-6,5/6,5-R	16	450	6,5	6,5	1
11008441	HELU-MB-CUV 16-400-8,5/8,5-R	16	400	8,5	8,5	1
11008448	HELU-MB-CUV 16-500-8,5/8,5-R	16	500	8,5	8,5	1
11008449	HELU-MB-CUV 16-600-8,5/8,5-R	16	600	8,5	8,5	1
11008450	HELU-MB-CUV 16-1200-8,5/8,5-R	16	1200	8,5	8,5	1
18049208	HELU-MB-CUV 25-100-8,5/8,5-R	25	100	8,5	8,5	1
18050349	HELU-MB-CUV 25-150-8,5/8,5-R	25	150	8,5	8,5	1
11008461	HELU-MB-CUV 25-200-8,5/8,5-R	25	200	8,5	8,5	1
18050351	HELU-MB-CUV 25-250-8,5/8,5-R	25	250	8,5	8,5	1
11008462	HELU-MB-CUV 25-300-8,5/8,5-R	25	300	8,5	8,5	1
18050352	HELU-MB-CUV 25-350-8,5/8,5-R	25	350	8,5	8,5	1
18050353	HELU-MB-CUV 25-400-8,5/8,5-R	25	400	8,5	8,5	1
18049209	HELU-MB-CUV 25-500-8,5/8,5-R	25	500	8,5	8,5	1
18049210	HELU-MB-CUV 30-100-10,5/10,5-R	30	100	10,5	10,5	1
18049211	HELU-MB-CUV 30-200-10,5/10,5-R	30	200	10,5	10,5	1
18049212	HELU-MB-CUV 30-300-10,5/10,5-R	30	300	10,5	10,5	1
18049213	HELU-MB-CUV 30-500-10,5/10,5-R	30	500	10,5	10,5	1
18049214	HELU-MB-CUV 35-100-10,5/10,5-R	35	100	10,5	10,5	1
18049215	HELU-MB-CUV 35-200-10,5/10,5-R	35	200	10,5	10,5	1
18049216	HELU-MB-CUV 35-300-10,5/10,5-R	35	300	10,5	10,5	1
18050354	HELU-MB-CUV 35-450-6,5/6,5-R	35	450	6,5	6,5	1
11009170	HELU-MB-CUV 35-500-8,5/8,5-R	35	500	8,5	8,5	1
18049217	HELU-MB-CUV 35-500-10,5/10,5-R	35	500	10,5	10,5	1
18049218	HELU-MB-CUV 50-100-10,5/10,5-R	50	100	10,5	10,5	1
18049219	HELU-MB-CUV 50-200-10,5/10,5-R	50	200	10,5	10,5	1
18049220	HELU-MB-CUV 50-300-10,5/10,5-R	50	300	10,5	10,5	1
18049221	HELU-MB-CUV 50-500-10,5/10,5-R	50	500	10,5	10,5	1
18049222	HELU-MB-CUV 70-300-12,5/12,5-R	70	300	12,5	12,5	1
18049223	HELU-MB-CUV 70-500-16,5/16,5-R	70	500	16,5	16,5	1