



## Qoltec Network SWITCH | 8 x RJ45 port | 100Mbps | Fast Ethernet | LAN

Product code: 52246

The network switch is a powerful device that provides stable and fast connections. It has 8 RJ45 ports for connecting devices on the local network. The maximum signal transmission distance is 150 metres, making it suitable for extensive network installations.

### DISCOVER THE FULL POTENTIAL OF YOUR NETWORK



### Stable and fast local network

If you are looking for a reliable and efficient network device that provides you with a stable and fast connection and smooth data transmission, then our switch from Qoltec is the ideal choice. Thanks to its innovative technology and robust design, **our device guarantees stable and smooth signal transmission from a single source to up to seven devices simultaneously**. This functionality allows for an exceptional expansion of the possibilities of use and exploitation of the multimedia system, **without the need for additional complex solutions or costly investments** in additional equipment. Now you can enjoy your favourite films, video games or presentations on several receivers simultaneously.

## FUNCTIONALITY ALWAYS AT HAND




### Range up to 150m, full duplex, 8 RJ45 ports with automatic crossover and interference protection

Discover new possibilities with the Qoltec device that offers:

- Signal distance up to 150m,
- **Equipped with 8 RJ45 ports**, each port has an automatic line crossover function,
- 10Mbps at 14880 packets per second, 100Mbps at 14800 packets per second,
- Enables efficient data exchange in full duplex mode compliant with IEEE802.3X, half duplex data flow control,
- Supports up to 1024 MAC addresses,
- **The unit is also distinguished by 8-pin shielded ports** to protect against electromagnetic interference, and an efficient heat dissipation system to ensure reliable operation even under intensive loads,
- **Has LEDs**, which provide information on the current operation of the device,

## EXPAND YOUR MULTIMEDIA CAPABILITIES

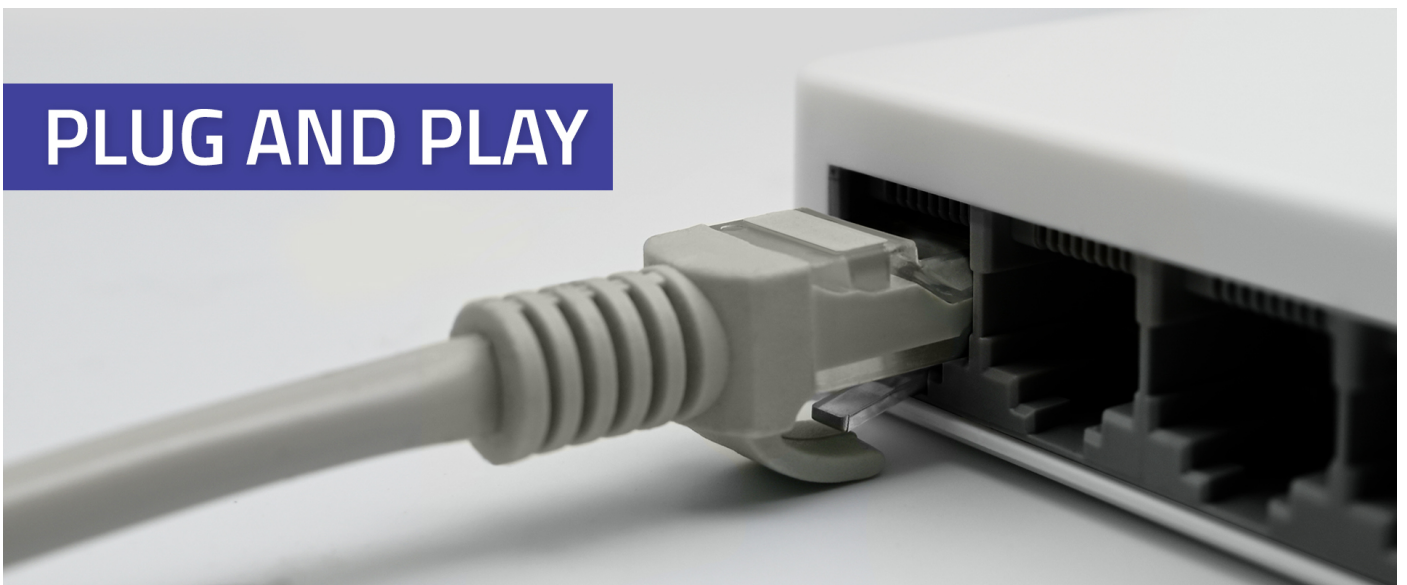

### Simple and quick installation

Our device **offers instant and trouble-free installation**, thanks to Plug & Play technology, which requires no additional configuration or technical expertise. You only need to follow a few simple steps. Firstly, **connect the devices to the appropriate RJ45 ports using the appropriate network cables** and then connect one of the ports to your router or access modem. Make sure the LEDs on the switch indicate activity on the ports.

## TRUST CONFIRMED BY WARRANTY

### Product with 24 months guarantee

Do you care about the high quality of the product you buy? Our solutions will meet your expectations. **The product is covered by a 24-month warranty** valid from the day of purchase.

## TECHNICAL DATA

|                             |                                                    |
|-----------------------------|----------------------------------------------------|
| Producer                    | Qoltec                                             |
| Max. bandwidth              | 1.6Gbps                                            |
| Max. baud rate              | 100Mbps                                            |
| Interface                   | RJ45                                               |
| Power supply                | 5-12V / 0.6A                                       |
| Usage                       | Communication, Internet, Server, Router            |
| Colour                      | White                                              |
| Working temperature         | -10 C ~ 55                                         |
| Dimensions (D/L x W x H)    | 56 x 126 x 21 mm                                   |
| Package                     | Box                                                |
| Package contents            | 1 x SWITCH<br>1 x Power Adapter<br>1 x User manual |
| Package depth / length [mm] | 65                                                 |
| Package width [mm]          | 130                                                |
| Package height [mm]         | 60                                                 |
| Net weight [kg]             | 0.128                                              |
| Gross weight [kg]           | 0.165                                              |
| Warranty                    | 24 months                                          |
| EAN code                    | 5901878522463                                      |