


AC1250



AS-Interface data decoupling module

AS-i Data Decoupler

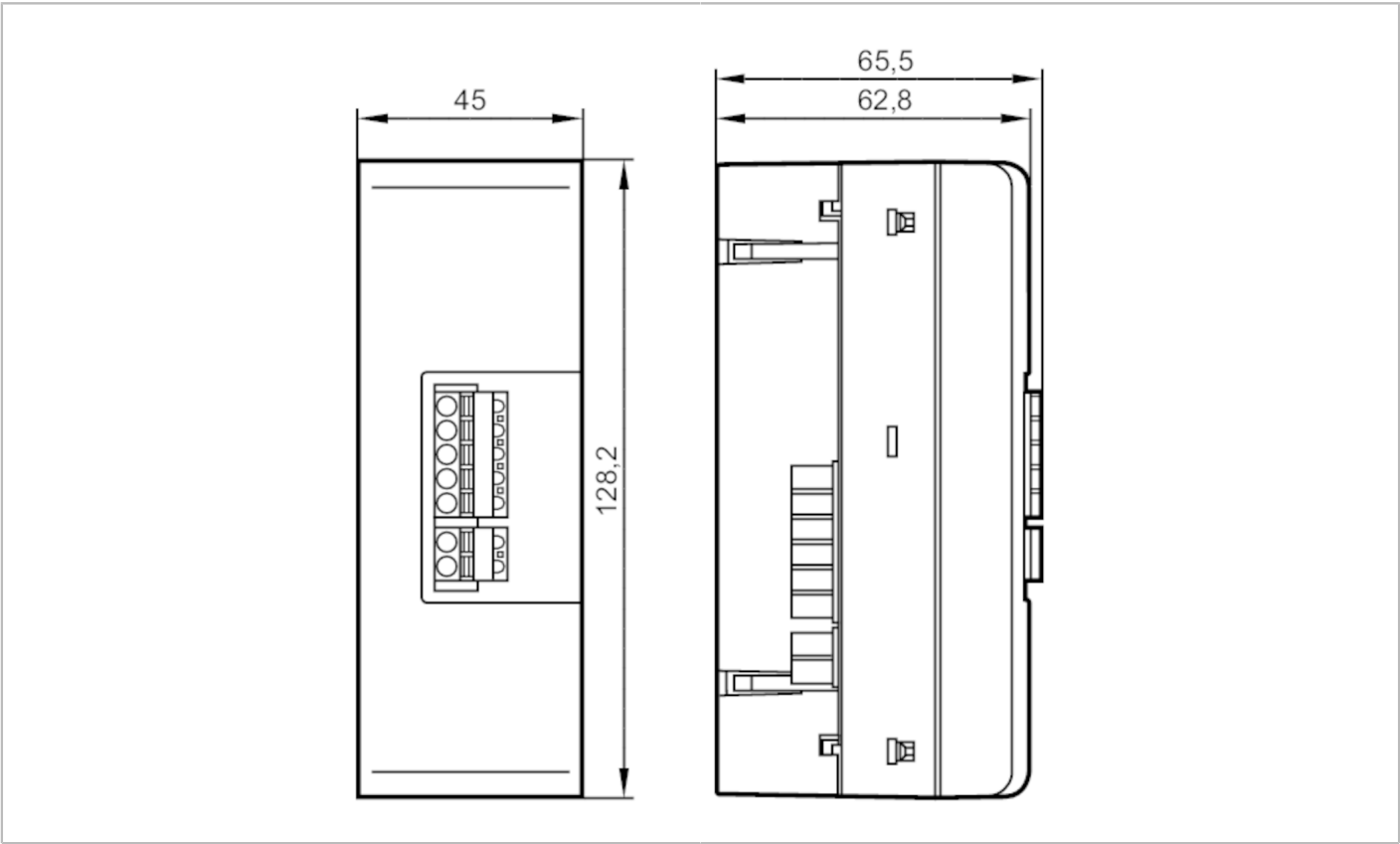

Electrical data		
Operating voltage	[V]	21.5...31.6 DC
Reverse polarity protection		yes
Outputs		
Short-circuit proof		yes
Electrically separated		no
Operating conditions		
Ambient temperature	[°C]	0...60
Storage temperature	[°C]	-20...70
Protection		IP 20
Tests / approvals		
MTTF	[years]	701
AS-i classification		
AS-i certificate		93001
Mechanical data		
Weight	[g]	263.5
Housing		rectangular
Dimensions	[mm]	128.2 x 45 x 65.5
Materials		PC

AC1250



AS-Interface data decoupling module

AS-i Data Decoupler

Remarks

Pack quantity	1 pcs.
---------------	--------

Electrical connection

...2.5 mm²

Connection

