




Multifunction display for monitoring revolution, speed and time

DISPLAY/FX460/AC/DC

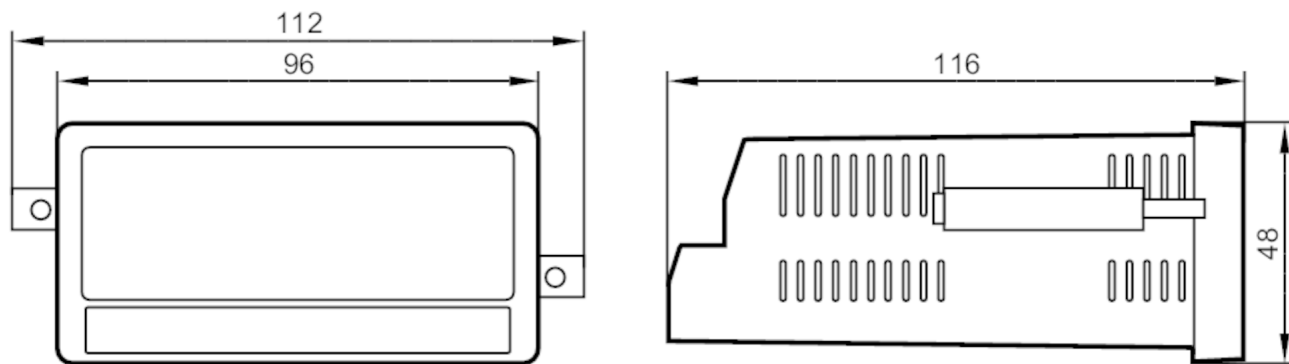

panel cutout 91 x 43 mm



Product characteristics

Dimensions [mm] 48 x 112 x 116

Application

Application universal evaluation and display for all physical units which can be derived from pulse sequences

Electrical data

Frequency AC	[Hz]	50...60
Operating voltage	[V]	115...230 AC / 18...30 DC
Current consumption	[mA]	100

Inputs / outputs

Number of inputs and outputs Number of digital inputs: 2

Inputs

Number of digital inputs 2

Operating conditions

Ambient temperature	[°C]	-20...60
Storage temperature	[°C]	-25...70
Protection		IP 65
Protection rating terminals		IP 20

Tests / approvals

EMC	EN 61000-6-2	
	EN 61000-6-3	
	EN 61000-6-4	

Mechanical data

Weight	[g]	355
Type of mounting		panel cutout: 91 x 43 mm
Dimensions	[mm]	48 x 112 x 116
Materials		Noryl UL94-V-0

Displays / operating elements

Display	colour display	full graphic LCD display, touch screen
---------	----------------	--




Multifunction display for monitoring revolution, speed and time

DISPLAY/FX460/AC/DC

Electrical connection

screw terminals:

Connection

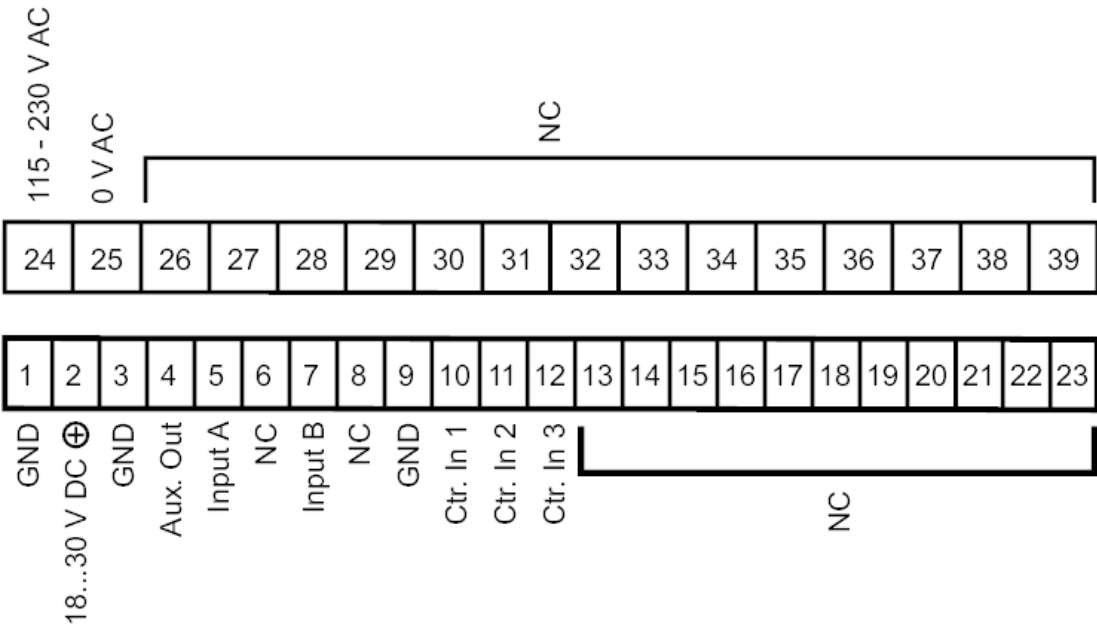

NC: not used